

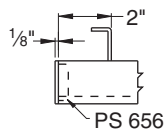
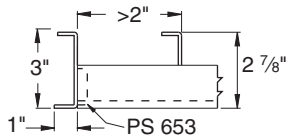
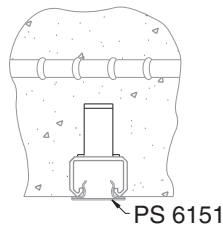
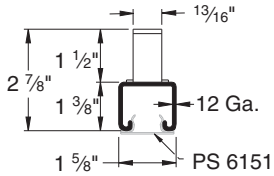


CONCRETE INSERTS

Finish: Plain, Hot-Dipped Galvanized, or Pregalvanized **Stock Length:** 20', Other lengths made to order
Stock Thickness: .105 (12 ga.) **Order By:** No., Size, Length and Finish

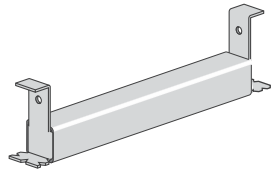

PS 349 – Continuous Concrete Insert (1 5/8" x 1 3/8")

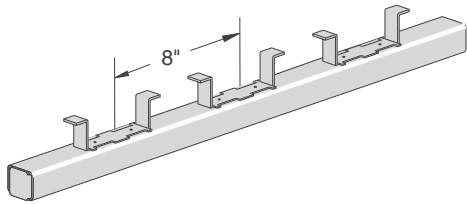


Choice of end cap is based on the distance from the end of the insert to the first anchor as shown below.

Furnished with steel end caps and plastic closure strips installed

- Use channel nuts designed for PS 300 Channel.
- Nail or anchor the inserts to forms every 16" to 24"

Part No.	End Cap	Wt./100 pcs - PLN	Load Data*	
PS 349 3" CS/EC	PS 653	72	500 lbs.	
PS 349 4" CS/EC		87	600 lbs.	
PS 349 6" CS/EC		117	800 lbs.	
PS 349 8" CS/EC		147	1,200 lbs.	
PS 349 1' CS/EC		194	2,000 lbs./ft.	
PS 349 1'4" CS/EC	PS 656	253		
PS 349 1'8" CS/EC	PS 653	312		
PS 349 2' CS/EC	PS 656	371		
PS 349 2'8" CS/EC		490		
PS 349 3' CS/EC	PS 653	549		
PS 349 4' CS/EC	PS 656	727		
PS 349 5' CS/EC	PS 653	905		
PS 349 6' CS/EC	PS 656	1,082		
PS 349 7' CS/EC	PS 653	1,260		
PS 349 8' CS/EC	PS 656	1,438		
PS 349 9' CS/EC	PS 653	1,615		
PS 349 10' CS/EC	PS 656	1,793		
PS 349 12' CS/EC		2,148		
PS 349 14' CS/EC		2,504		
PS 349 16' CS/EC		2,859		
PS 349 18' CS/EC		3,215		
PS 349 20' CS/EC		3,570		
PS 349 10' W/O	Insert Only	1,777		*uniform recommended loading on inserts in 3,000 psi concrete.
PS 349 20' W/O		3,554		


PS 653 – Type 'B' End Cap

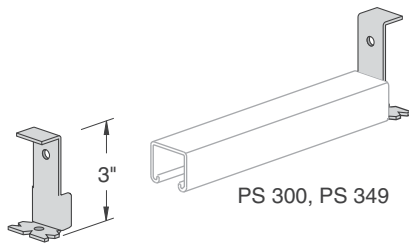

Finish: Pre-galvanized

Weight/100 pcs: 14 lbs.


PS 654 – Type 'B' End Cap

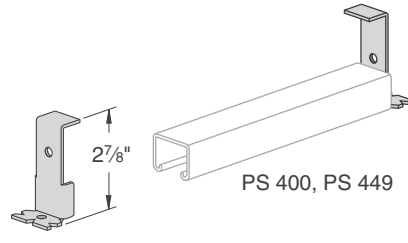

Finish: Pre-galvanized

Weight/100 pcs: 12 lbs.

PS 1154 – Splice Connection

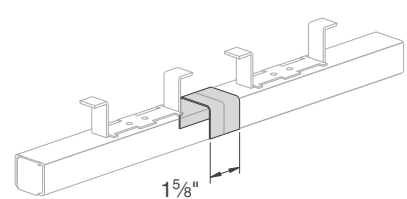

Use With: PS 349

Weight/100 pcs: 10 lbs.