



| | |
|-----------------|-------|
| CATALOG NUMBER: | |
| JOB NAME: | |
| CUSTOMER NAME: | |
| NOTES: | TYPE: |
| | DATE: |

FEATURES AND SPECIFICATIONS

WALL LIGHTING
WLD18 SERIES
18" DIE CAST WALL LIGHT

Wattages:

Pulse Start: 200w - 250w Ⓢ
 High Pressure Sodium: 250w

Construction:

Die Cast Aluminum Housing
 High Output Full Reflector
 Face Frame Opens to the Side
 Shallow Back Design
 Threaded Apertures for Conduit & Photo Control

Optics:

Borosilicate Glass Lens

Electrical:

UL Listed for Wet Locations


Specifications:

Overall height: 9.01" (22.88 cm)
 Width: 18.2" (46.21 cm)
 Depth: 9.78" (24.8412 cm)
 Weight: 32 lbs / 14.51 kg.



ORDERING INFORMATION

Order accessories as separate catalog numbers (shipped separately).

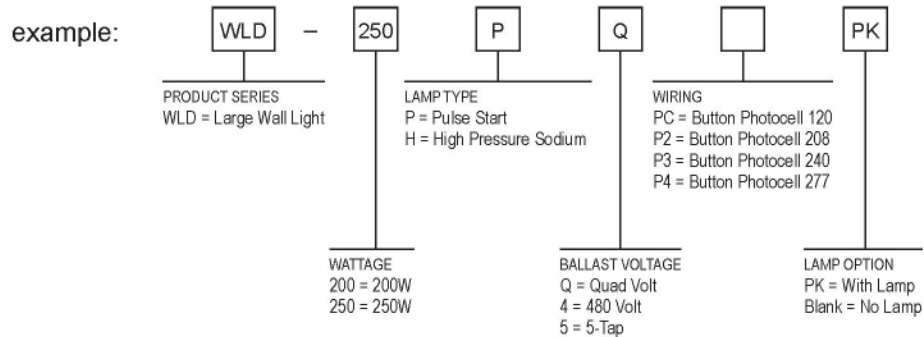


Actual performance can vary depending on operating conditions. Specifications are subject to change without notice.

DIMENSIONS

Specifications:


Overall height:
9.01" (22.88 cm)

Width:
18.2" (46.21 cm)

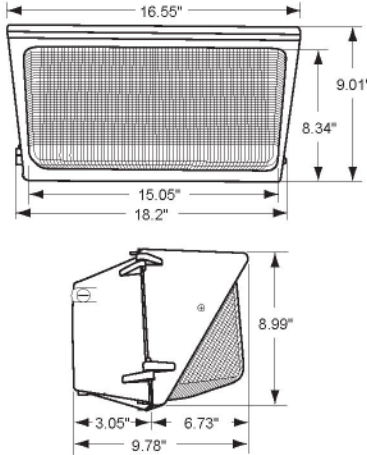


PHOTOMETRICS

250W PS @ 15' Mounting Height

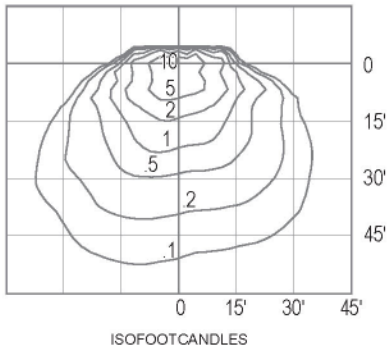

MOUNTING DETAILS

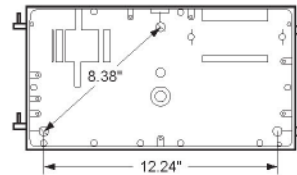

Actual performance can vary depending on operating conditions. Specifications are subject to change without notice.