



CATALOG NUMBER:	
JOB NAME:	
CUSTOMER NAME:	
NOTES:	TYPE:
	DATE:

**FEATURES AND SPECIFICATIONS**

**WALL LIGHTING**  
**WLM13 SERIES**  
**13" DIE CAST WALL LIGHT**

**Wattages:**

- Pulse Start: 70w - 150w ⓔ
- High Pressure Sodium: 70w - 150w
- Fluorescent: 52w - 84w

**Construction:**

- Die Cast Aluminum Housing
- Threaded Apertures for Conduit & Photo Control
- Face Frame Opens to the Side
- Emergency Battery Backup Available

**Optics:**

- Borosilicate Glass Lens

**Electrical:**

- UL Listed for Wet Locations

**Specifications:**

- Overall height: 9.02" (22.91 cm)
- Width: 14.2" (36.06 cm)
- Weight: 18 lbs / 8.16 kg.




**ACCESSORIES**

- 280-019-1 Wireguard for WLM
- 280-022-1 Polycarbonate Guard for WLM
- 320-013 Full Cut-Off Shield for WLM-Bronze
- 210-007 WLM Face Frame Assembly-Bronze
- 230-002 Button 120V Photo Control
- 230-008 Button 208-277V Photo Control

**ORDERING INFORMATION**

Order accessories as separate catalog numbers (shipped separately).

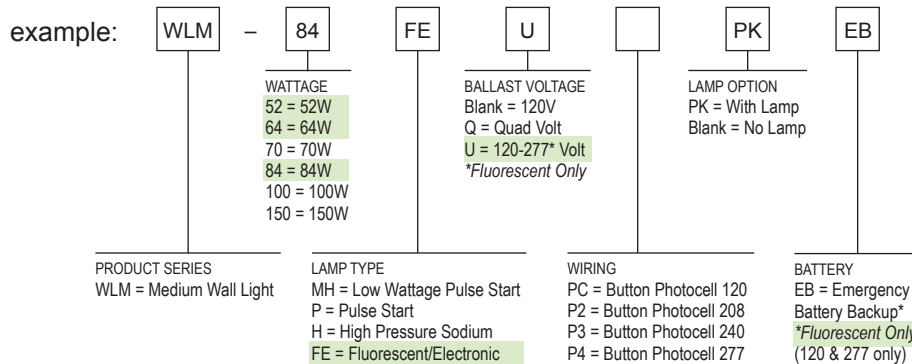

Actual performance can vary depending on operating conditions. Specifications are subject to change without notice.