

- Die Cast Aluminum Housing
- Borosilicate Glass Lens
- High Output Full Reflector
- Face Frame Opens to the Side
- Threaded Apertures for Conduit & Photo Control





quick SHIP Products

CATALOG #	DESCRIPTION	VOLTS	BALLAST TYPE	LAMP
Pulse Start				
Ⓔ WLXD-320PQPK	320 watt PS	Quad	CWA	MS320/H
Ⓔ WLXD-400PQPK	400 watt PS	Quad	CWA	MS400/H
High Pressure Sodium				
WLXD-400HQPK	400 watt HPS	Quad	CWA	C400S51

480V Available Upon Request


Dimensions

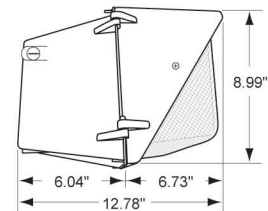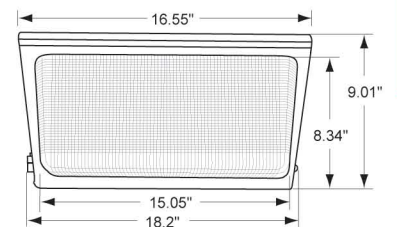


Accessories

CATALOG #	DESCRIPTION	STD. PKG.
280-020-1	Wireguard for WLXD	1
280-023-1	Polycarbonate Guard for WLXD	1
320-015	Full Cut-Off Shield for WLXD-Bronze	1
210-011	WLXD Face Frame Assembly-Bronze	1
230-002	Button 120V Photo Control	1
230-008	Button 208-277V Photo Control	1

Mounting Detail

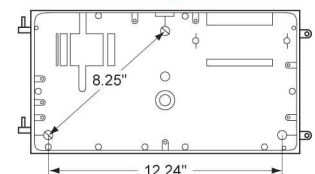


Ordering Format

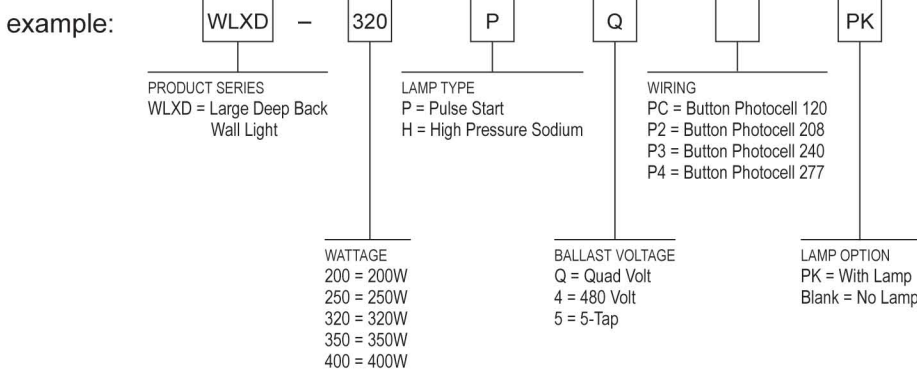

Photometrics

400W PS @ 25' Mounting Height

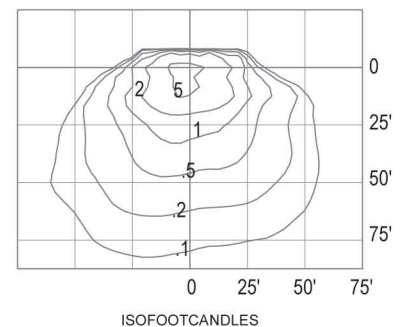

Wall Lighting
18" Die Cast Deep Back

