

MORE FOOTCANDLES

LUMENS: **4,274**  
 WATTS: **43**  
 LUMENS PER WATT: **98**  
 CRI: **72**      DIMMING: **10-100%**

**200,000+ HOURS**



**OPTICS MATTER**

**PFM43LED**



**Alpha Series LED**  
 PROFESSIONAL GRADE

Design is Protected by US Patent D710,530



**ORDERING INFORMATION**

CATALOG #	DESCRIPTION	WATTS	VOLTS	CCT
<b>PFM43LED</b>	43W LED Power Flood Pro	43	120-277	4500K




- PFM43LED - standard beam spread 60°  
 - NEMA type 4Hx4V (medium distribution)
- 105° optics available for wall wash and accent lighting where less intensity is required  
 - NEMA type 6Hx6V (extra wide distribution)

**OPTIONS**

ADD SUFFIX #	DESCRIPTION
PC	120V Photocontrol
PM	208-277V Photocontrol


**DIMENSIONS AND SPECIFICATIONS**

**Overall Height:** 9.36"  
**Overall Width:** 6.36"  
**Depth:** 7.53"  
**Weight:** 10 lbs.

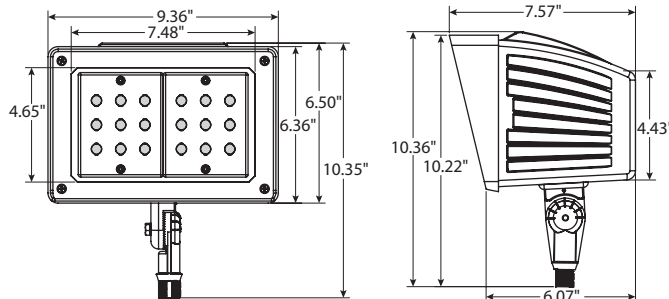

**PHOTOMETRICS**

NEMA type 4Hx4V

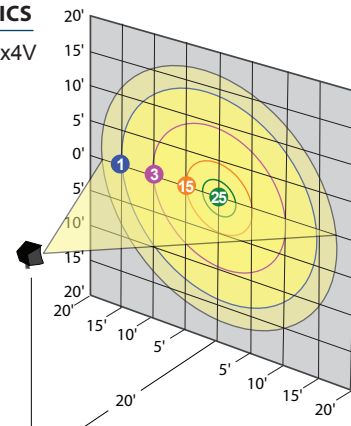

**LED COMPARISON CHART**

175W METAL HALIDE

ATLAS 43W LED

**FLOOD LIGHTS**



**210 INPUT WATTS**



**43 INPUT WATTS**

TOTAL YEARLY COST INC. MAINT.	\$112	\$19
TOTAL YEARLY SAVINGS	-	\$93
POTENTIAL ONE TIME REBATE	\$0	\$50
TOTAL FIRST YEAR SAVINGS	-	\$143
DOLLAR RETURN IN 3 YEARS	-	\$329

Based on 12 hours per day | \$0.10/kWh  
 Utility Rates & Rebates Vary by Location

**84% ANNUAL SAVINGS**

**Less Than 3 Year Payback**

