

Wet Location FLUORESCENT 4 & 6 Lamp

Hinged Ballast Tray
Stainless Steel Latches
Composite Housing
Poured Gasket
IP67 Rated
NSF Rated
NEMA 4x Rated





Ordering Information

CATALOG #	# OF LAMPS	FIXTURE LENGTH	LAMP WATTS	VOLTS	BALLAST TYPE	LAMPS INCLUDED
IFW4454UEP5	4	4'	54	Unv.	T5HOPS	F54T5HO/841
IFW4432UEI8	4	4'	32	Unv.	T8IS	F32T8/841
IFW4654UEP5	6	4'	54	Unv.	T5HOPS	F54T5HO/841
IFW4632UEI8	6	4'	32	Unv.	T8IS	F32T8/841

Dimensions and Specifications

Overall Height: 6.25" (15.88 cm)
Overall Width: 14.375" (36.51 cm)
Length: 51.5" (130.81 cm)

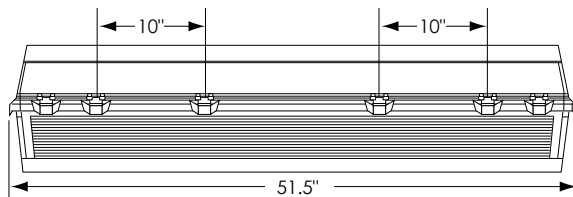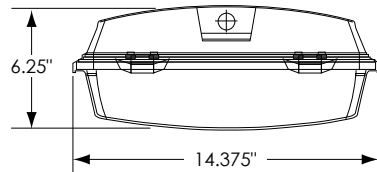

Options

SUFFIX #	DESCRIPTION	SUFFIX #	DESCRIPTION
3C*	3' Cord (No Plug)	L	Stainless Steel Latches
F	Inline Fusing	83	835 Lamps
N	No Lamps	85	850 Lamps

*Also Available in 6', 10' and 20' length

Accessories

CATALOG #	DESCRIPTION
MS360WL	Wet Location 360° Motion Sensor
80-271CMB	Ceiling Mount Bracket

Ambient Temperature Fixture Rating

PART #	DESCRIPTION	12" CHAIN MOUNT
IFW4454UEP5	4 ft., 4 Lamp, 54w T5HO	104°F/40°C
IFW4432UEI8	4 ft., 4 Lamp, 32w T8	104°F/40°C
IFW4654UEP5	4 ft., 6 Lamp, 54w T5HO	86°F/30°C
IFW4632UEI8	4 ft., 6 Lamp, 32w T8	95°F/35°C



*The majority of Atlas Lighting Products are assembled in USA facilities by an American Workforce utilizing both Domestic and Foreign components

