

# Aisle Lighter FLUORESCENT

## 4' & 8'



Tool-less Entry

24 Gauge Housing



Miro-4 ≥ 95% Reflectance

### Ordering Information


CATALOG #	# OF LAMPS	LAMP WATTS	VOLTS	BALLAST TYPE	OPTICS	LAMPS INCLUDED
IFA4254UEP5	2	54	Unv.	T5HO	Miro-4	F54T5HO/841
IFA4232UEI8	2	32	Unv.	T8	Miro-4	F32T8/841
IFA8254UEP5	4	54	Unv.	T5HO	Miro-4	F54T5HO/841
IFA8232UEI8	4	32	Unv.	T8	Miro-4	F32T8/841

### Dimensions and Specifications

**Overall Height:** 4.38" (11.13 cm)

**Overall Width:** 9.13" (23.19 cm)

**Length:** 4' (121.92 cm)  
8' (243.84 cm)

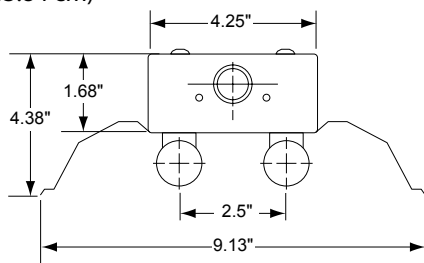

### OPTIONS

SUFFIX #	DESCRIPTION	SUFFIX #	DESCRIPTION
3C*	3' Cord (No Plug)	F	Inline Fusing
3T*	3' 120V Cord & Plug	N	No Lamps
3E*	3' 208V Cord & Plug	EB	Emergency Back-Up
3F*	3' 240V Cord & Plug	83	835 Lamps
3S*	3' 277V Cord & Plug	85	850 Lamps
3I*	3' 480V Cord & Plug	M	Motion Sensor**

\*Also Available in 6', 10' and 20' length

\*\*T5 or PS Ballast Required

### ACCESSORIES

CATALOG #	DESCRIPTION
CH36	Chain Set
CH36HFC	Chain Set w/Hammer-On Flange Clip
CA36	Cable Set
MS360	360° Motion Sensor

### Ambient Temperature Fixture Rating

PART #	DESCRIPTION	12" CHAIN MOUNT
IFA4254UEP5	4 ft., 2 Lamp, 54w T5HO	131°F/55°C
IFA4232UEI8	4 ft., 2 Lamp, 32w T8	131°F/55°C
IFA8254UEP5	8 ft., 4 Lamp, 54w T5HO	131°F/55°C
IFA8232UEI8	8 ft., 4 Lamp, 32w T8	113°F/45°C



\*The majority of Atlas Lighting Products are assembled in USA facilities by an American Workforce utilizing both Domestic and Foreign components

