

# FLL

## 16" Die Cast Flood Light

### 200 - 400 watts PS | HPS


#### SERIES




- Die Cast Aluminum Housing
- Hinged Face Frame
- Tempered Glass Lens
- High Output Reflector
- UL Listed for Ground Mounting
- Pre-wired with Cord

**quick SHIP Products**

#### Dimensions

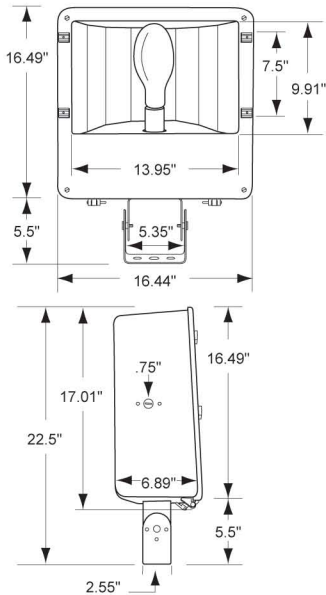


#### Mounting Detail

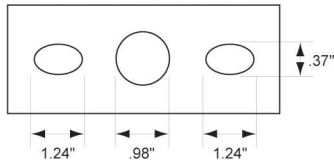

#### Photometrics

400W PS @ 25' Mounting Height

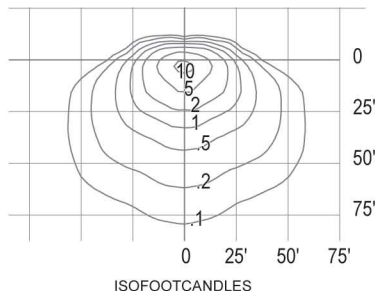

CATALOG #	DESCRIPTION	VOLTS	BALLAST	LAMP
<b>Pulse Start</b>				
Ⓔ FLL-250PQPK	250 watt PS	Quad	CWA	MS250/H
Ⓔ FLL-320PQPK	320 watt PS	Quad	CWA	MS320/H
Ⓔ FLL-350PQPK	350 watt PS	Quad	CWA	MS350/H
Ⓔ FLL-400PQPK	400 watt PS	Quad	CWA	MS400/H
<b>High Pressure Sodium</b>				
FLL-400HQPK	400 watt HPS	Quad	CWA	C400S51

For Slipfitter Add Suffix "S"

Please Consult page 199 for PS Lamp Orientation

#### Accessories

CATALOG #	DESCRIPTION	STD. PKG.
320-007	Glare Shield for FLL - Bronze	1
320-006	Wireguard for FLL	1
320-005	Baffle for FLL - Bronze	1
280-016-1	Slipfitter for FLL with Cord - Bronze	1
210-003	FLL Face Frame Assembly - Bronze	1
280-017	Trunion for FLL/FLLS - Bronze	1

#### Ordering Format

example:

