

52 - 150 watts
PS | HPS | FL

9" Die Cast Square
FLM

SERIES



- Die Cast Aluminum Housing
- Hinged Face Frame
- Tempered Glass Lens
- ½" Heavy Duty Knuckle or Slipfitter
- UL Listed for Ground Mounting




quick SHIP Products

CATALOG #	DESCRIPTION	VOLTS	BALLAST	LAMP
Pulse Start				
FLM-70MHQPK	70 watt PS	Quad	HX-HPF	MH70/U/M
FLM-100MHQPK	100 watt PS	Quad	HX-HPF	MH100/U/M
FLM-150PQPK	150 watt PS	Quad	HX-HPF	MS150/U/M
High Pressure Sodium				
FLM-70HPK	70 watt HPS	120	R-NPF	C70S62/M
FLM-100HQPK	100 watt HPS	Quad	HX-HPF	C100S54/M
FLM-150HPK	150 watt HPS	120	R-NPF	C150S55/M
FLM-150HQPK	150 watt HPS	Quad	HX-HPF	C150S55/M
Fluorescent				
FLM-84FEUPK	84 watt FL	Univ.	Prog. Start	(2) PLT42W/41

For Slipfitter Add Suffix "S"
Please Consult page 199 for PS Lamp Orientation


Dimensions

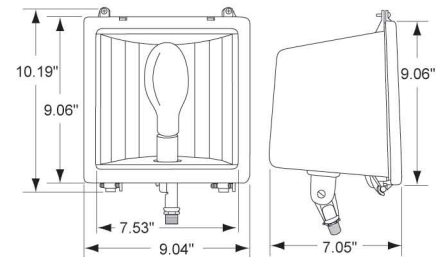


Accessories

CATALOG #	DESCRIPTION	STD. PKG.
210-004	FLM Face Frame Assembly - Bronze	1
320-020	Glare Shield for FLM - Bronze	1
320-021	Wireguard for FLM	1


Ordering Format

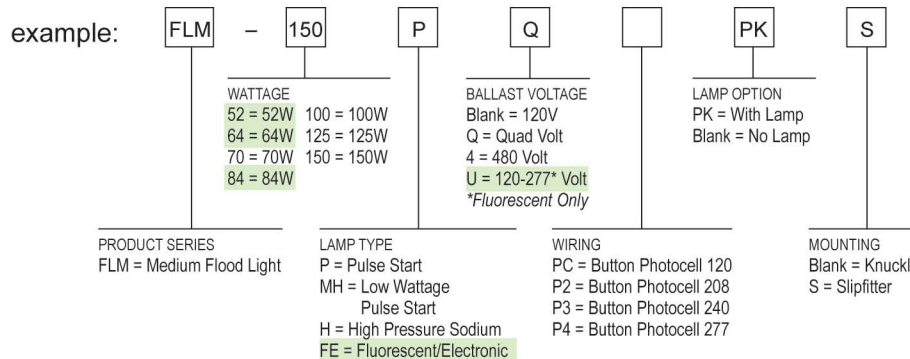

Mounting Detail
Knuckle

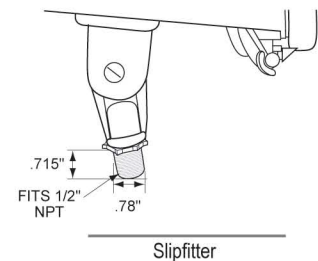


Slipfitter

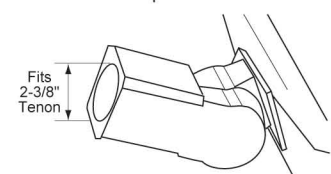

Photometrics

150W PS @ 15' Mounting Height

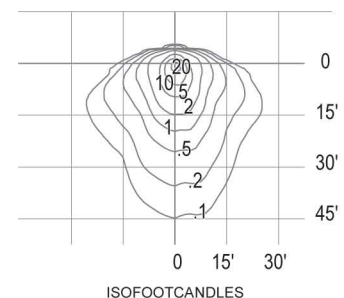

MH vs. Fluorescent

	100w MH	84w FL
Lamp Life	10,000 hrs	12,000 hrs
Start Up Time	3-5 minutes	Instant
Restrike Time	15-20 minutes	Instant
CRI	70	82
Color Temperature	4,200k	4,100k
Initial Lumens	7,800	6,400
Mean Lumens	5,600	5,500
Mean Lumens/Watt	43.4	65.52
Watts/Fixture	129	84
Cost/Year*	\$30.13	\$19.62

*Based On: 8 hours per day | 365 days per year | \$0.08 per kWh



Flood Lighting

9" Die Cast Square