

IFS

6 Lamp T5 | T8
Full Bodied High Bay

TITANTM
FLUORESCENT HIGH BAY

SERIES

Fluorescent Industrial


Full Bodied High Bay



Chain



Cable

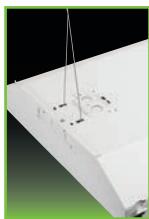

Toggle



Pendant

Inline Fusing Available



Suitable for 50° Ambient Operation



Quick Wire Access Panel

Full Bodied 20 Gauge Housing Provides Protection for Optical Assembly

Post Painted Polyester Coat Finish

Hinged Optics for Access Without Removal of Lamps or Reflector



Miro-4 or White Reflector



Options & Accessories


| CATALOG # | DESCRIPTION | STD. PKG. | SUFFIX # | DESCRIPTION |
|-----------------------|--|-----------|----------|--------------------------|
| Mounting | | | | |
| CH36 | 36" Chain Set | 1 | 3C | 3' Cord (No Plug) |
| CH36HFC | 36" Chain Set w/ Hammer-On Flange Clip | 1 | 3T | 3' 120V Cord & Plug |
| CA36 | 36" Cable Set | 1 | 3E | 3' 208V Cord & Plug |
| 280-255-S | Tandem Mounting Kit | 1 | 3F | 3' 240V Cord & Plug |
| PMK | Pendant Mount Kit | 1 | 3S | 3' 277V Cord & Plug |
| TM36 | Toggle Mount Kit | 1 | 3I | 3' 480V Cord & Plug |
| Motion Sensors | | | | |
| MS360 | 360° Motion Sensor | 1 | F | Inline Fusing |
| Wireguards | | | | |
| WG36 | Wireguard for 6 Lamp Titan Units | 1 | N | No Lamps |
| Door Frames | | | | |
| LFP36-125 | Prismatic Lens for 6 Lamp Titan Units | 1 | EB | Emergency Ballast Backup |
| LFC36-125 | Clear Lens for 6 Lamp Titan Units | 1 | 83 | 835 Lamps - 3500K |
| | | | 85 | 850 Lamps - 5000K |
| | | | M | Motion Sensor |
| | | | P | Pendant Mount |

See pages 30-31 for more accessories



Miro-4 ≥ 95% Reflectance

Dimensions

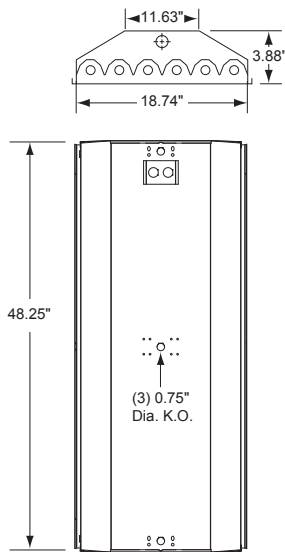

quick SHIP Products

| CATALOG # | # OF LAMPS | LAMP WATTS | VOLTS | BALLAST TYPE | OPTICS | LAMP |
|--------------|------------|------------|-------|--------------|--------|-------------|
| IFS4632UEI8 | 6 | 32 | UNV | T8IS | Miro-4 | F32T8/841 |
| IFS4632UEI8W | 6 | 32 | UNV | T8IS | White | F32T8/841 |
| IFS4654UEP5 | 6 | 54 | UNV | T5HOPS | Miro-4 | F54T5HO/841 |
| IFS4654UEP5W | 6 | 54 | UNV | T5HOPS | White | F54T5HO/841 |

UNV = 120-277V 480V Available Upon Request

Ordering Format

example:

| | | | | | | | |
|---|--|---|--|--|---|---|--|
| <div style="border: 1px solid black; padding: 2px; width: 40px; margin: 0 auto;">IFS</div> <p>PRODUCT SERIES IFS = Steel Industrial Fluorescent</p> | <div style="border: 1px solid black; padding: 2px; width: 40px; margin: 0 auto;">4</div> <p>FIXTURE LENGTH 4 = 4 Feet 8 = 8 Feet* *Tandem Mount Kit Included</p> | <div style="border: 1px solid black; padding: 2px; width: 40px; margin: 0 auto;">6</div> <p>LAMPS 6</p> | <div style="border: 1px solid black; padding: 2px; width: 40px; margin: 0 auto;">54</div> <p>WATTAGE 32 = 32W T8 54 = 54W T5HO</p> | <div style="border: 1px solid black; padding: 2px; width: 40px; margin: 0 auto;">U</div> <p>VOLTAGE U = Universal (120-277) 4 = 480 Volt</p> | <div style="border: 1px solid black; padding: 2px; width: 40px; margin: 0 auto;">EP5</div> <p>BALLAST E18 = T8 Electronic Instant Start EP8 = T8 Electronic Program Start EP5 = T5HO Electronic Program Start</p> | <div style="border: 1px solid black; padding: 2px; width: 40px; margin: 0 auto;">W</div> <p>OPTICS Blank = Miro-4 W = White</p> | <div style="border: 1px solid black; padding: 2px; width: 40px; margin: 0 auto;">3C</div> <p>OPTIONS 3C = 3' Cord (No Plug) 3T = 3' 120V Cord & Plug 3E = 3' 208V Cord & Plug 3F = 3' 240V Cord & Plug 3S = 3' 277V Cord & Plug 3I = 3' 480V Cord & Plug F = Inline Fusing N = No Lamps EB = Emergency Ballast 83 = 835 Lamps 85 = 850 Lamps M = Motion Sensor P = Pendant Mount</p> |
|---|--|---|--|--|---|---|--|

Wireguard



Toolless Entry



Hinged

Door Frame



Toolless Entry



Hinged

Motion Sensor



Emergency Ballast

