



CATALOG NUMBER:	
JOB NAME:	
CUSTOMER NAME:	
NOTES:	TYPE:
	DATE:



FEATURES AND SPECIFICATIONS

FLUORESCENT INDUSTRIAL LIGHTING

RFS SERIES STRIP RETROFIT KITS

Optics:

- Convert F96 Lamps to F32 or F54 Lamps
- One and Two Lamp Options
- Relamp 1' x 4' or 1' x 8' Fixtures

Electrical:

- Toolless Ballast Access
- Prewired for Faster Installation
- ≥ 20kHz
- PF > .9
- THD < 20%
- See other side for component detail

Specifications:

- Width: 5.65" (14.35 cm)
- Length: 48" to 96" (121.92 to 243.84 cm)

Warranty:

Atlas Lighting Products provides a 3 year limited warranty for this product. A full warranty can be found at www.alpinc.com


Fixture Efficiency >90%

CRI ≥ 81


UL 1598B Listed as Luminaire Conversion, Retrofit



ORDERING INFORMATION

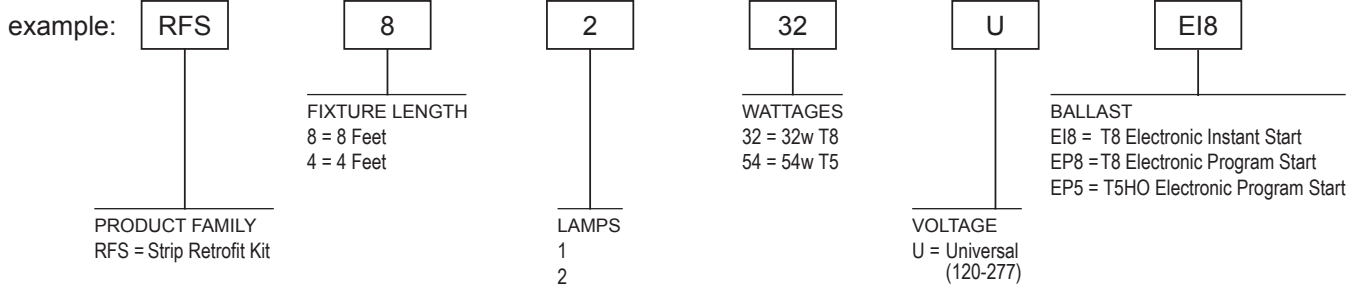

DIMENSIONS

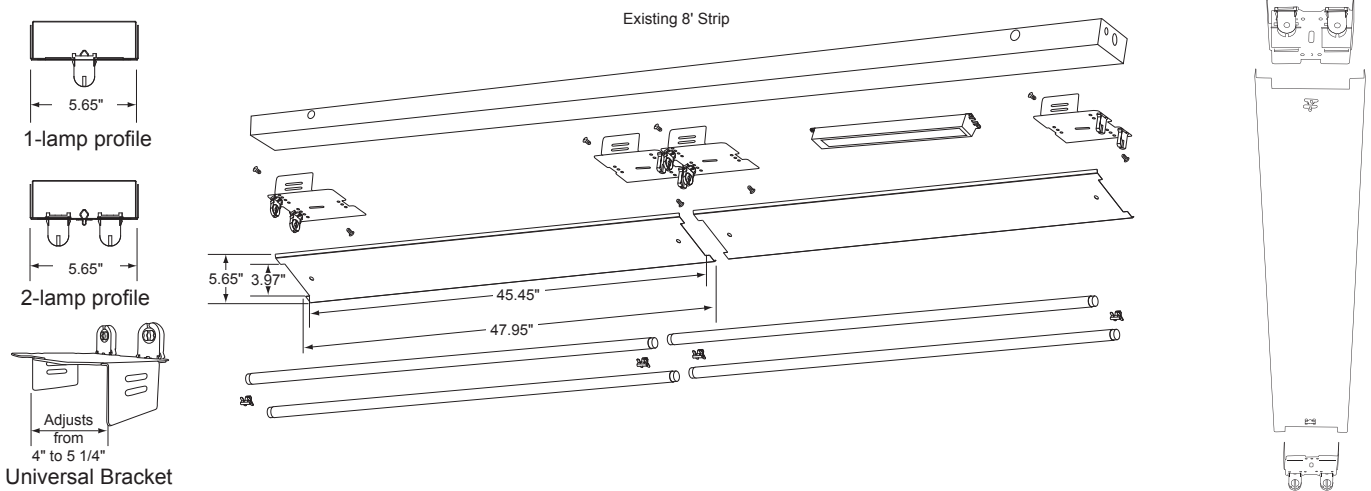

Actual performance can vary depending on operating conditions. Specifications are subject to change without notice.

ATLAS LIGHTING PRODUCTS, INC.

PO BOX 2348 | BURLINGTON, NC 27216
800-849-8485 | FAX: 336-227-0110 | www.atlaslightingproducts.com



FLUORESCENT INDUSTRIAL LIGHTING
RFS SERIES
STRIP RETROFIT KITS



COMPONENT SPECS

RFS Series													
FIXTURE NUMBER	BALLAST PART #	QTY	BALLAST FACTOR	INPUT WATTS	CEE	LAMP	WATTAGE PART #	QTY	LUMENS	LIFE	CRI	CCT	CEE
RFS4132UEIN8	EB232UI	1	0.88	30		F32T8/841	32	1	3100	20K+	82	4100	
RFS4132UEI8	EB232UIH	1	1.18	42	YES	F32T8/841	32	1	3100	20K+	82	4100	
RFS4154UEP5	EB254UP	1	1	63	N/A	F54T5/841	54	1	4450	20K+	82	4100	
RFS4232UEIN8	EB232UI	1	0.88	59		F32T8/841	32	2	3100	20K+	82	4100	
RFS4232UEI8	EB232UIH	1	1.18	76	YES	F32T8/841	32	2	3100	20K+	82	4100	
RFS4254UEP5	EB254UP	1	1	116	N/A	F54T5/841	54	2	4450	20K+	82	4100	
RFS8132UEIN8	EB232UI	1	0.88	59		F32T8/841	32	2	3100	20K+	82	4100	
RFS8132UEI8	EB232UIH	1	1.18	76	YES	F32T8/841	32	2	3100	20K+	82	4100	
RFS8154UEP5	EB254UP	1	1	116	N/A	F54T5/841	54	2	4450	20K+	82	4100	
RFS8232UEIN8	EB432UI	1	0.88	112		F32T8/841	32	4	3100	20K+	82	4100	
RFS8232UEI8	EB432UIH	1	1.2	140	YES	F32T8/841	32	4	3100	20K+	82	4100	
RFS8254UEP5	EB454UP	1	1	232	N/A	F54T5/841	54	4	4450	20K+	82	4100	

Actual performance can vary depending on operating conditions. Specifications are subject to change without notice.