



CATALOG NUMBER:	
JOB NAME:	
CUSTOMER NAME:	
NOTES:	TYPE:
	DATE:

FEATURES AND SPECIFICATIONS

WALL LIGHTING

WL11 SERIES

11" WALL LIGHT WITH POLYCARBONATE LENS



Wattages:

High Pressure Sodium: 35W - 70w
Fluorescent: 26w

Construction:

Polycarbonate Housing
Aluminum Base Plate with Conduit Access
Corrosion Resistant

Optics:

Polycarbonate Lens

Electrical:

UL Listed for Wet Locations


Specifications:

Overall height: 10.95" (27.80 cm)
Width: 6.83" (17.33 cm)
Weight: 6 lbs. / 2.72 kg.

ORDERING INFORMATION

Choose the boldface catalog nomenclature that best suits your needs and write it on the appropriate line. Order accessories as separate catalog numbers (shipped separately).

example:

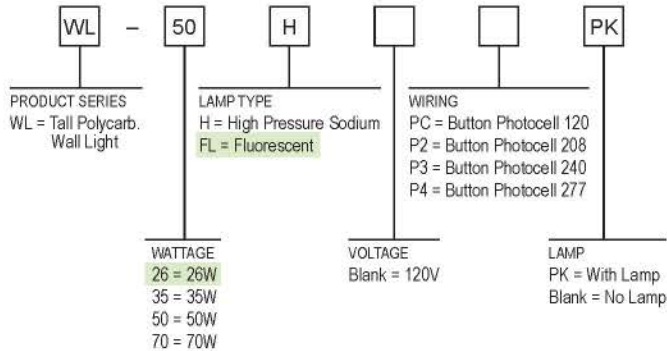

Actual performance can vary depending on operating conditions. Specifications are subject to change without notice.


DIMENSIONS

Specifications:

Overall height:
 10.948" (27.80 cm)


Width:
 6.825" (17.33 cm)

Weight:
 6 lbs. / 2.72 kg.

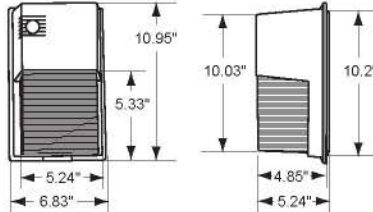


PHOTOMETRICS

70W HPS @ 15' Mounting Height

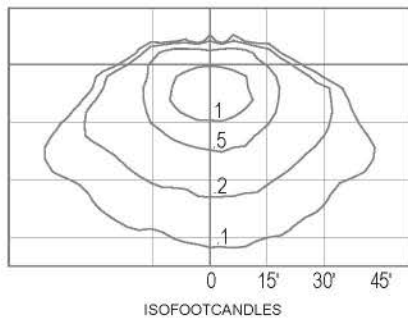

MOUNTING DETAILS

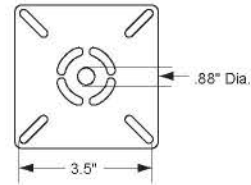

Actual performance can vary depending on operating conditions. Specifications are subject to change without notice.