
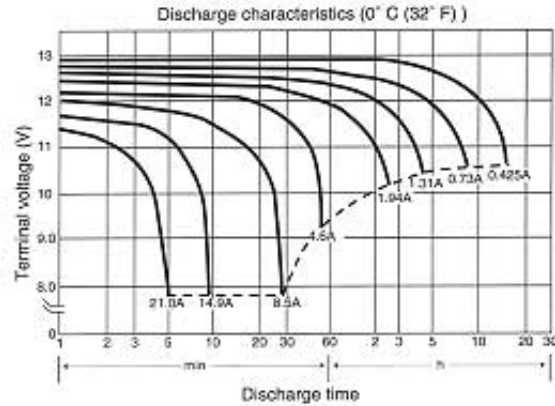


HIGH DENSITY PM Type Sealed Lead-Acid Battery


PM1285[®]

• **Specification & Characteristics**

Type	PM1285	
Nominal voltage	12V	
Rated capacity	8.5 Ah/20HR	
Dimensions	Length	151mm (5.95 inches)
	Width	66mm (2.60 inches)
	Container Height	96mm (3.78 inches)
Weight	Approx. 2.7Kg (5.97 lbs.)	
Capacity 20°C (68°F)	20 HR 0.425 A	8.5 Ah
	5 HR 1.31 A	6.55 Ah
	1 HR 4.6 A	4.6 Ah
	1C 8.5 A	4.25 Ah
Internal resistance	Approx. 25 mΩ	
Max. Discharge current	40A (5 sec)	
Charging voltage 20°C (68°F)	Standby	13.5~13.8V (-20mV/C)
	Cycle use	14.4~15.0V (-30mV/C)
Max. Charging Current	1.95A	

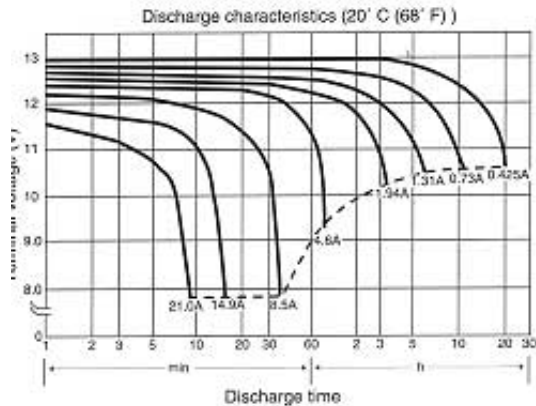

Dimensions

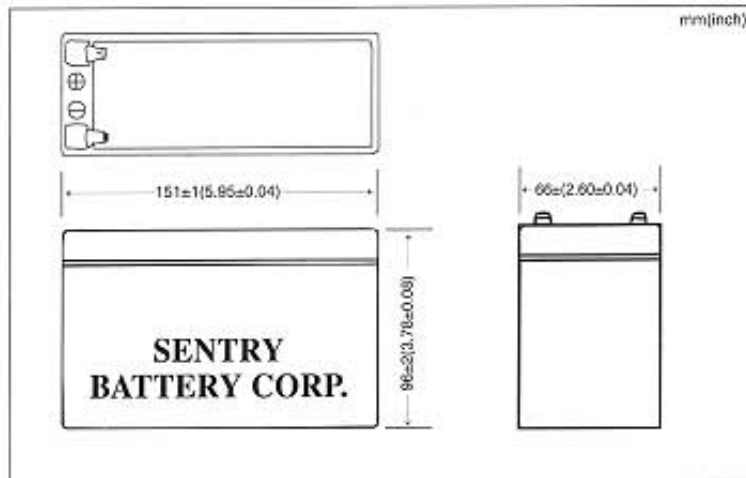

Terminal

