

Multi-Color Indicators — K50L Series

- ▶ 50 mm Dome-Shaped Polycarbonate Housing with 30 mm Threaded Mounting Base
- ▶ Multi-Color and/or Flashing Frequencies: Three, Four or Five Color Models
- ▶ Energy Efficient Low Power Consumption with a Long Life (100,000 Hours Typical)
- ▶ IP67 Rated, Fully Encapsulated Design
- ▶ Accessories Available: Cordsets, Brackets and Mounting Solutions



Stock No.	Mfr.'s Type	Connection	LED Function	Input	Voltage	EACH
70167587	K50LGRYP	2 m Cable	3 Color: Green, Red, Yellow	PNP	18-30 VDC	74.95
70167588	K50LGRYPQ	4-Pin Euro QD	3 Color: Green, Red, Yellow	PNP	18-30 VDC	74.95
70167589	K50LGRY2P	2 m Cable	3 Color: Choose Green, Red or Yellow ON, Flashing or Alternating	PNP	18-30 VDC	84.95
70167590	K50LGRY2PQ	4-Pin Euro QD	3 Color: Choose Green, Red or Yellow ON, Flashing or Alternating	PNP	18-30 VDC	84.95
70167591	K50LGRYB4P	2 m Cable	4 Color: Choose Green, Red, Yellow or Blue ON, Flashing or Alternating	PNP	18-30 VDC	95.95
70167592	K50LGRYB4PQ	5-Pin Euro QD	4 Color: Choose Green, Red, Yellow or Blue ON, Flashing or Alternating	PNP	18-30 VDC	95.95
70167593	K50LGRYBWP	2 m Cable	5 Color: Choose Green, Red, Yellow, Blue or White ON, Flashing or Alternating	PNP	18-30 VDC	105.95
70167594	K50LGRYBWPQ8	8-Pin Euro QD	5 Color: Choose Green, Red, Yellow, Blue or White ON, Flashing or Alternating	PNP	18-30 VDC	105.95
70167595	K50LGRYA120Q	5-Pin Micro QD	3 Color: Green, Red, Yellow	PNP	85-130 VAC	87.95

Multi-Color — K50FL Flat Pack Series

- ▶ 50 mm Dome-Shaped ABS/Polycarbonate Housing for Flat Mounting
- ▶ Multi-Color and/or Flashing Frequencies: Three, Four or Five Color Models
- ▶ Energy Efficient Low Power Consumption with a Long Life (100,000 Hours Typical)
- ▶ IP67 Rated, Fully Encapsulated Design
- ▶ Accessories Available: Cordsets, Brackets and Mounting Solutions



Stock No.	Mfr.'s Type	Connection	LED Function	Input	Voltage	EACH
70167697	K50FLGRYP	2 m Cable	3 Color: Green, Red, Yellow	PNP	18-30 VDC	74.95
70167698	K50FLGRYPQ	4-Pin Euro QD	3 Color: Green, Red, Yellow	PNP	18-30 VDC	74.95
70167699	K50FLGRY2P*	2 m Cable	3 Color: Green, Red, Yellow	PNP	18-30 VDC	84.95
70167691	K50FLGRY2PQ*	5-Pin Euro QD	3 Color: Green, Red, Yellow	PNP	18-30 VDC	84.95
70167692	K50FLGRYB4P*	2m Cable	4 Color: Green, Red, Yellow, Blue	PNP	18-30 VDC	95.95
70167693	K50FLGRYB4PQ*	5-Pin Euro QD	4 Color: Green, Red, Yellow, Blue	PNP	18-30 VDC	95.95
70167694	K50FLGRYBWP*	2 m Cable	5 Color: Green, Red, Yellow, Blue, White	PNP	18-30 VDC	105.95
70167695	K50FLGRYBWPQ8*	8-Pin Euro QD	5 Color: Green, Red, Yellow, Blue, White	PNP	18-30 VDC	105.95

*ON, Flashing or Alternating.

Audible Indicators — K50L Series

- ▶ Dome-Shaped Polycarbonate Housing with 30 mm Threaded Mounting Base
- ▶ Green, Red and Yellow Indication
- ▶ Audible Tone Indication; Two Decibel Levels with Steady or Pulsed Tone
- ▶ Energy Efficient Low Power Consumption with a Long Life (100,000 Hours Typical)
- ▶ IP50 Rated
- ▶ 18-30 VDC Supply Voltage and PNP Input
- ▶ Accessories Available: Cordsets, Brackets and Mounting Solutions



Stock No.	Mfr.'s Type	Connection	Audible Tone (dB)	Inputs	EACH
70167598	K50LGRA1YP	2 m Cable	Steady (75)	PNP	100.95
70167599	K50LGRA1YPQ	5-Pin Euro QD	Steady (75)	PNP	100.95
70167600	K50LGRA2YP	2 m Cable	Pulsed (75)	PNP	110.95
70167601	K50LGRA2YPQ	5-Pin Euro QD	Pulsed (75)	PNP	110.95
70167602	K50LGRAL1YP	2 m Cable	Loud (95)	PNP	110.95
70167603	K50LGRAL1YPQ	5-Pin Euro QD	Loud (95)	PNP	110.95

Battery Powered Flashing Call Light — K80 Series


Banner's portable, battery-powered K80 Call Lights provide operational status indication for personnel and is ideal in locations where power is limited or unavailable. The pre-assembled housing and multiple mounting options make the indicator light cost-effective and easy-to-install.

- ▶ Flashes ON/OFF
- ▶ Switch Activated
- ▶ No Assembly Required
- ▶ Rugged and Easy-to-Install
- ▶ Long-Life LED Technology Gives Up to 100 Hours of Operation on Two 9V Batteries (Included)

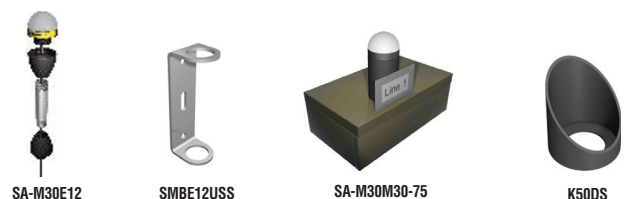
Stock No.	Mfr.'s Type	LED Function	Input	Power Supply	EACH
70279621	K80CLR	Red, 1 Second Flashing Rate	ON/OFF Switch	2 — 9V Batteries (Included)	98.95

Omni-Directional High-Intensity Indicators — K50 Beacon Series

- ▶ Bright Light, Visible from Side and Front, Ideal for Indoor and Outdoor Use
- ▶ 1 or 2 Color Models Available. Choose from 5 Colors
- ▶ UV Stabilized Rugged, Sealed Housing IP67 and IP69K Rated



Stock No.	Mfr.'s Type	Connection	LED Color	Input	Voltage	EACH
70279622	K50BCLXGXPQ	4-Pin Euro QD	Green	PNP	12-30 VDC	98.95
70279623	K50BCLXRXXPQ	4-Pin Euro QD	Red	PNP	12-30 VDC	98.95
70279158	K50BCLGRXPQ	4-Pin Euro QD	Green/Red	PNP	12-30 VDC	98.95
70279650	K50BCLGA230Q	4-Pin Euro QD	Green	PNP	100-250 VAC	98.95
70279651	K50BCLRA230Q	4-Pin Euro QD	Red	PNP	100-250 VAC	98.95

Indicator Accessories and Mounting Solutions — K50L


Stock No.	Mfr.'s Type	Description	Length (mm)	EACH
70167604	SA-M30E12	Thermoplastic Acetal Adapter/Cover	—	10.99
70167605	SOP-E12-150SS	Stainless-Steel Pipe	150	14.99
70167606	SOP-E12-300SS	Stainless-Steel Pipe	300	22.99
70167607	SA-E12M30	Thermoplastic Acetal Base	—	10.99
70167608	SMBE12USS	Stainless-Steel Mounting Bracket	—	14.99
70167609	SA-M30M30-75	Thermoplastic Acetal Standoff with 30 mm Mounting Base for Cabinet Mounting	75	15.99
70167610	K50DS	Thermoplastic Polyester Sun Shield	—	5.99