


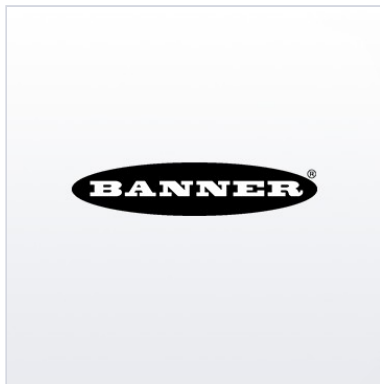

MBCC-306

► ITEM DETAIL SINGLE-ENDED CORDSETS



CERTIFICATIONS



Mini-style Quick Disconnect
Cable

3 Pin Female Pin-out Straight
Connector

2 m (6.5 ft) in Length

Nylon coupling nut

Part Number: 45132

FACTORY	IN
STOCK:	STOCK

LIST PRICE	\$41.00
(USD):	

SPECIFICATIONS

Number of Contacts	3
Number of Connectors	1
Cable Jacket Material	PVC
Cable Jacket Color	Black
Connector Body Material/Color	PUR Black
Outside Cable Diameter (mm)	7
Cordset Length (m)	1.83

Trunk Length (m)	No Trunk
Shield/No Shield	No Shield
Coupling Material/Color	Nylon Black
Maximum Temp. (°C)	105
Minimum Temp. (°C)	-40
IP Rating	IP67
Primary Connector Type	MINI
Primary Coupling Method	7/8"-16
Primary Gender	Female
Primary Orientation	Straight
Primary Number of Conductors	3
Primary AWG	18
Secondary Connector Type	Flying Leads
Feature: Hazardous Area	No
Feature: Chemical Resistant	No
Oil/Grease Resistant	No



