


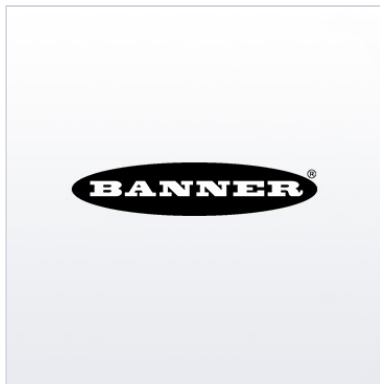

# MBCC-412

## ▶ ITEM DETAIL SINGLE-ENDED CORDSETS



### CERTIFICATIONS



Mini-style Quick Disconnect Cable  
 4 Pin Female Pin-out Straight Connector  
 4 m (12 ft) in Length  
 Nylon coupling nut  
 Part Number: 25226

<b>FACTORY STOCK:</b>	<b>IN STOCK</b>
-----------------------	-----------------

<b>LIST PRICE (USD):</b>	<b>\$46.00</b>
--------------------------	----------------

### SPECIFICATIONS

<b>Number of Contacts</b>	4
<b>Number of Connectors</b>	1
<b>Cable Jacket Material</b>	PVC
<b>Cable Jacket Color</b>	Black
<b>Connector Body Material/Color</b>	PUR Black
<b>Outside Cable Diameter (mm)</b>	7
<b>Cordset Length (m)</b>	3.66

<b>Trunk Length (m)</b>	No Trunk
<b>Shield/No Shield</b>	No Shield
<b>Coupling Material/Color</b>	Nylon Black
<b>Maximum Temp. (°C)</b>	105
<b>Minimum Temp. (°C)</b>	-40
<b>IP Rating</b>	IP67
<b>Primary Connector Type</b>	MINI
<b>Primary Coupling Method</b>	7/8"-16
<b>Primary Gender</b>	Female
<b>Primary Orientation</b>	Straight
<b>Primary Number of Conductors</b>	4
<b>Primary AWG</b>	18
<b>Secondary Connector Type</b>	Flying Leads
<b>Feature: Hazardous Area</b>	No
<b>Feature: Chemical Resistant</b>	No
<b>Oil/Grease Resistant</b>	No



