


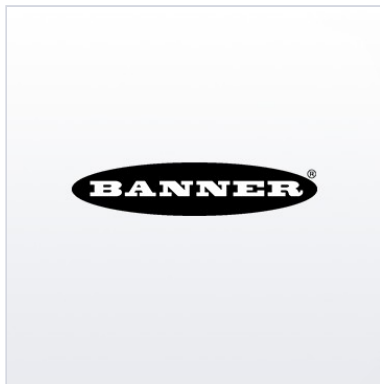

MQDC-406

► ITEM DETAIL SINGLE-ENDED CORDSETS



CERTIFICATIONS



Euro-style Quick Disconnect
Cable
4-Pin Straight Connector
2 m (6.5 ft) in Length
Chrome plated brass coupling
nut
Part Number: 45136

FACTORY	IN
STOCK:	STOCK

LIST PRICE	\$21.00
(USD):	

SPECIFICATIONS

Number of Contacts	4
Number of Connectors	1
Cable Jacket Material	PVC
Cable Jacket Color	Black
Connector Body Material/Color	PUR Black
Outside Cable Diameter (mm)	5.2
Cordset Length (m)	1.83

Trunk Length (m)	No Trunk
Shield/No Shield	No Shield
Coupling Material/Color	Nickel Plated Brass
Maximum Temp. (°C)	105
Minimum Temp. (°C)	-40
IP Rating	IP67
Primary Connector Type	EURO
Primary Coupling Method	M12 Single Key
Primary Gender	Female
Primary Orientation	Straight
Primary Number of Conductors	4
Primary AWG	22
Secondary Connector Type	Flying Leads
Feature: Hazardous Area	No
Feature: Chemical Resistant	No
Oil/Grease Resistant	No



