


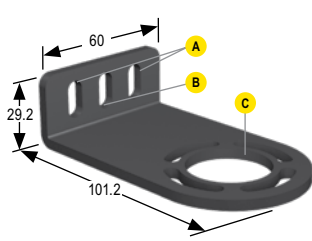


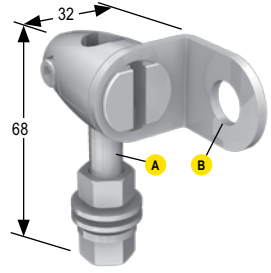

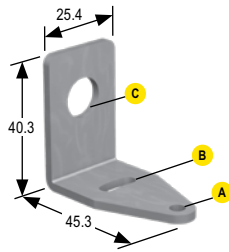

SMA-MBK-1	SMB12FA..	SMB12MM	SMB1812SF						
 <p>All measurements in mm</p>	 <p>All measurements in mm</p>	 <p>All measurements in mm</p>	 <p>All measurements in mm</p>						
<p>Hole center spacing: A = 31.5, A to B = 15.8 Hole size: A, B = 15 X 7, C = ø 32</p>	<table border="1"> <thead> <tr> <th>Model</th> <th>Bolt Thread (A)</th> </tr> </thead> <tbody> <tr> <td>SMB12FA</td> <td>3/8 - 16 x 2"</td> </tr> <tr> <td>SMB12FAM10</td> <td>M10 - 1.5 x 50</td> </tr> </tbody> </table> <p>Hole size: B = ø 12.1</p>	Model	Bolt Thread (A)	SMB12FA	3/8 - 16 x 2"	SMB12FAM10	M10 - 1.5 x 50	<p>Hole center spacing: A to B = 26 Hole size: A = ø 4.6, B = 12.8 x 4.6, C = ø 12.3</p>	<p>Hole center spacing: A = 36.1 Hole size: A = ø 5, B = ø 12</p>
Model	Bolt Thread (A)								
SMB12FA	3/8 - 16 x 2"								
SMB12FAM10	M10 - 1.5 x 50								
<ul style="list-style-type: none"> • Two-bracket replacement kit for brackets that come with SSM Mirrors • 8-ga. cold-rolled steel with black corrosion-resistant zinc chromate finish • Bracket hardware included 	<ul style="list-style-type: none"> • Swivel bracket with tilt and pan movement for precision adjustment • Easy sensor mounting to extruded rail T-slots • Metric and inch size bolts available • 12 mm sensor mounting hole 	<ul style="list-style-type: none"> • ±10° of lateral movement • 12-ga. stainless steel • Mounting holes for M4 (#6) hardware • 12 mm sensor mounting hole 	<ul style="list-style-type: none"> • Swivel bracket with 12 mm mounting hole • Black reinforced thermoplastic polyester • Stainless steel mounting and swivel locking hardware included 						
End Mount	Barrel Mount	Barrel Mount	Barrel Mount						
 <p>Used with</p>	 <p>Used with</p>	 <p>Used with</p>	 <p>Used with</p>						
SSM Mirror	M12 S12	M12 S12 PICO-GUARD Switches PICO-GUARD Points	PICO-GUARD Points						

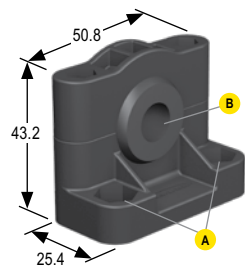