






	Part Number	Description	Light Source	Lamp Watts	Case Quantity	Example Photo	
LED EXIT SIGNS	RX3RWE	Emergency LED Exit Sign, Universal (single/double face), Red Letters, White Housing, 120/277 VAC, Damp Location Listed	LED	N/A	6		 
	RX3GWE	Emergency LED Exit Sign, Universal (single/double face), Green Letters, White Housing, 120/277 VAC, Damp Location Listed	LED	N/A	6		 
COMBINATION EXIT & EMERGENCY	CX3RW	Combination Exit and Emergency Lighting Unit, Red Letters, White Housing, Universal (single/double face), 120/277 VAC, Damp Location Listed	LED	5.4	5		 
	CX3GW	Combination Exit and Emergency Lighting Unit, Green Letters, White Housing, Universal (single/double face), 120/277 VAC, Damp Location Listed	LED	5.4	5		 
SIDE MOUNT FIXED LENS COMBINATION	FX3RW	Side Mount Fixed Lens Combination LED Exit and Emergency Lighting Unit, Red Letters, White Housing, Universal (single/double face), 120/277 VAC, Damp Location Listed	INC	5.4	5		 
	FX3GW	Side Mount Fixed Lens Combination LED Exit and Emergency Lighting Unit, Green Letters, White Housing, Universal (single/double face), 120/277 VAC, Damp Location Listed	INC	5.4	5		 
	FX3RWEC	Side Mount Fixed Lens Combination LED Exit and Emergency Lighting Unit, Red Letters, White Housing, Universal (single/double face), 120/277 VAC, Damp Location Listed, Extended Capacity to remote (2) 5.4 Watt Remote Heads	INC	5.4	5		 
	FX3GWEC	Side Mount Fixed Lens Combination LED Exit and Emergency Lighting Unit, Green Letters, White Housing, Universal (single/double face), 120/277 VAC, Damp Location Listed, Extended Capacity to remote (2) 5.4 Watt Remote Heads	INC	5.4	5		 
LOW PROFILE & 2-HEADED ADJUSTABLE	LPU	Low Profile Fixed Lens Emergency Lighting Unit, White Housing, 120/277 VAC, Damp Location Listed	INC	5.4	6		
	EM2	2-Headed Adjustable Emergency Lighting Unit, White Housing, 120/277 VAC, Damp Location Listed	INC	5.4	6		
INDOOR & OUTDOOR REMOTE HEAD	RXHSW0605	Matching Indoor Single Remote Head, 5.4 Watt Lamp, White Thermoplastic, Mounts to 3 1/2" octagon or single gang box	INC	5.4	10		
	RXHDW0605	Matching Indoor Double Remote Head, (2) 5.4 Watt Lamp, White Thermoplastic, Mounts to 3 1/2" octagon or single gang box	INC	5.4	5		
	ORHSG0605	Outdoor Sealed Single Remote Head, 5.0 Watt Lamp, Grey Thermoplastic, Mounts to 3 1/2" octagon or single gang box	INC	5.4	10		
	ORHDG0605	Outdoor Sealed Double Remote Head, (2) 5.0 Watt Lamp, Grey Thermoplastic, Mounts to 3 1/2" octagon or single gang box	INC	5.4	5		

# Side Mount Fixed Lens Combination Exit & Emergency Lighting Unit

Thermoplastic Housing Self Powered



Part #: FX3RWEC




Part #: FX3GWEC

## NOT SHOWN:

**FX3RW** - Side Mount Fixed Lens Combination Exit and Emergency Lighting Unit, Red Letters, White Housing, Universal (single/double face), 120/277VAC, Damp Location Listed

**FX3GW** - Side Mount Fixed Lens Combination Exit and Emergency Lighting Unit, Green Letters, White Housing, Universal (single/double face), 120/277VAC, Damp Location Listed

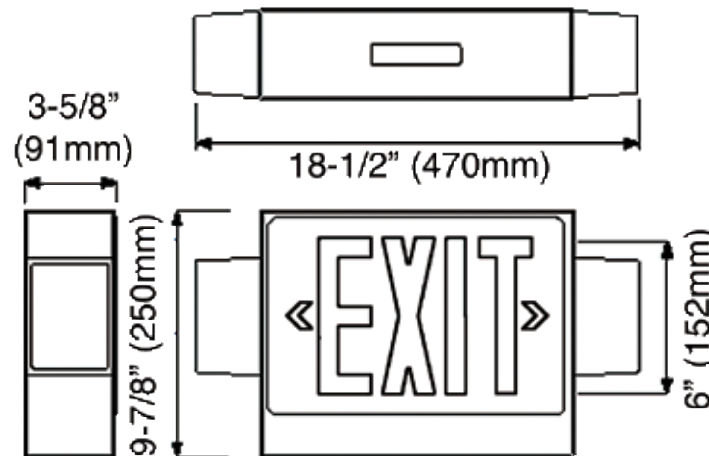

## DESCRIPTION

The Side Mount Fixed Lens Combination Exit and Emergency Lighting Units are economical and energy saving exit signs with two side mounted emergency lighting heads. The LED lamps provide a maximum of energy savings potential and the battery pack operates the unit to be self powered during power outages.

## APPLICATION

Suitable for use in almost any commercial or light industrial application. Ideal for mounting in the limited space available above doorways.

## EXTENDED REMOTE CAPACITY

Models with EC suffix provide up to 10.8 watts of extra capacity for remote unit operation.

## COMPLIANCE

UL924 Listed. UL listed for damp locations. Life Safety NFPA 101.

## HOUSING

The housing is made of injection molded thermoplastic, making it impact resistant and corrosion proof. UL94-5V rated.

## MOUNTING

Easy snap fit canopy can be used for top mounting or knockouts can be used for surface mounting. Included second face allows the unit to be used as a single or double face exit sign. Snap fitting, replaceable chevrons for direction indication.

## LAMPS

Long life Light Emitting Diode (LED) lamps in the exit sign portion provide the maximum in energy savings. The emergency lighting heads have 2 x 5.4 W adjustable incandescent lamps.

## ELECTRICAL/BATTERY

- Dual voltage input 120/277 VAC, 60 Hz.
- Maintenance free, Sealed Lead Calcium 6V, 4.5 AH battery with a maximum full recharge time of 48 hours. Minimum 1½ hour emergency operation.
- Low voltage disconnect of the battery prevents deep discharge and maintains good battery life.
- Fully automatic, solid state charger.
- Test switch with LED charge indicator/AC voltage indicator.
- Line latching feature prevents the unit from turning on during installation to a non-energized AC circuit.