






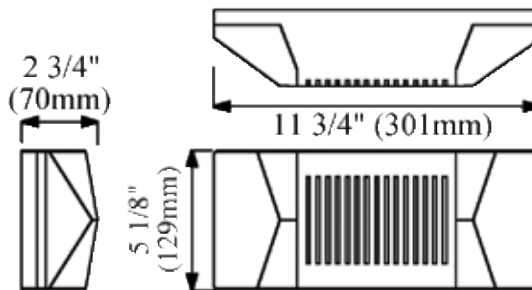
	Part Number	Description	Light Source	Lamp Watts	Case Quantity	Example Photo	
LED EXIT SIGNS	RX3RWE	Emergency LED Exit Sign, Universal (single/double face), Red Letters, White Housing, 120/277 VAC, Damp Location Listed	LED	N/A	6		 
	RX3GWE	Emergency LED Exit Sign, Universal (single/double face), Green Letters, White Housing, 120/277 VAC, Damp Location Listed	LED	N/A	6		 
COMBINATION EXIT & EMERGENCY	CX3RW	Combination Exit and Emergency Lighting Unit, Red Letters, White Housing, Universal (single/double face), 120/277 VAC, Damp Location Listed	LED	5.4	5		 
	CX3GW	Combination Exit and Emergency Lighting Unit, Green Letters, White Housing, Universal (single/double face), 120/277 VAC, Damp Location Listed	LED	5.4	5		 
SIDE MOUNT FIXED LENS COMBINATION	FX3RW	Side Mount Fixed Lens Combination LED Exit and Emergency Lighting Unit, Red Letters, White Housing, Universal (single/double face), 120/277 VAC, Damp Location Listed	INC	5.4	5		 
	FX3GW	Side Mount Fixed Lens Combination LED Exit and Emergency Lighting Unit, Green Letters, White Housing, Universal (single/double face), 120/277 VAC, Damp Location Listed	INC	5.4	5		 
	FX3RWEC	Side Mount Fixed Lens Combination LED Exit and Emergency Lighting Unit, Red Letters, White Housing, Universal (single/double face), 120/277 VAC, Damp Location Listed, Extended Capacity to remote (2) 5.4 Watt Remote Heads	INC	5.4	5		 
	FX3GWEC	Side Mount Fixed Lens Combination LED Exit and Emergency Lighting Unit, Green Letters, White Housing, Universal (single/double face), 120/277 VAC, Damp Location Listed, Extended Capacity to remote (2) 5.4 Watt Remote Heads	INC	5.4	5		 
LOW PROFILE & 2-HEADED ADJUSTABLE	LPU	Low Profile Fixed Lens Emergency Lighting Unit, White Housing, 120/277 VAC, Damp Location Listed	INC	5.4	6		
	EM2	2-Headed Adjustable Emergency Lighting Unit, White Housing, 120/277 VAC, Damp Location Listed	INC	5.4	6		
INDOOR & OUTDOOR REMOTE HEAD	RXHSW0605	Matching Indoor Single Remote Head, 5.4 Watt Lamp, White Thermoplastic, Mounts to 3 1/2" octagon or single gang box	INC	5.4	10		
	RXHDW0605	Matching Indoor Double Remote Head, (2) 5.4 Watt Lamp, White Thermoplastic, Mounts to 3 1/2" octagon or single gang box	INC	5.4	5		
	ORHSG0605	Outdoor Sealed Single Remote Head, 5.0 Watt Lamp, Grey Thermoplastic, Mounts to 3 1/2" octagon or single gang box	INC	5.4	10		
	ORHDG0605	Outdoor Sealed Double Remote Head, (2) 5.0 Watt Lamp, Grey Thermoplastic, Mounts to 3 1/2" octagon or single gang box	INC	5.4	5		

Emergency Light

Thermoplastic Housing Low Profile Fixed Heads



Part #: LPU



DESCRIPTION

The LPU is an attractive, economical alternative to traditional double headed emergency lighting fixtures. The appealing low profile design is quick and simple to install.

APPLICATION

Suitable for use in almost any commercial or light industrial application.

COMPLIANCE

UL924.
Life Safety NFPA 101.
UL listed for damp location use.

HOUSING

The housing is made of injection molded thermoplastic. It has high impact resistance and is UL94-5V rated.

MOUNTING

The back mounting plate is made of injection molded thermoplastic. It has a molded in universal J-Box mounting pattern and keyhole slots. The main housing snaps on to the back plate for quick and easy installation.

LENS

Computer designed optical prisms throw the light outward and to the sides for maximum utilization.


ELECTRICAL/BATTERY

- Dual voltage input 120/277 VAC, 60 Hz.
- Maintenance free, Sealed Lead Calcium 6V, 4.0 AH battery with a maximum full recharge time of 24 hours. Minimum 1½ hour emergency operation.
- Low voltage disconnect of the battery prevents deep discharge and maintains good battery life.
- Fully automatic, solid state charger.
- Test switch with LED charge indicator/AC voltage indicator.
- Line latching feature prevents the unit from turning on during installation to a non-energized AC circuit.

Thermoplastic Housing Square Heads



Part #: EM2

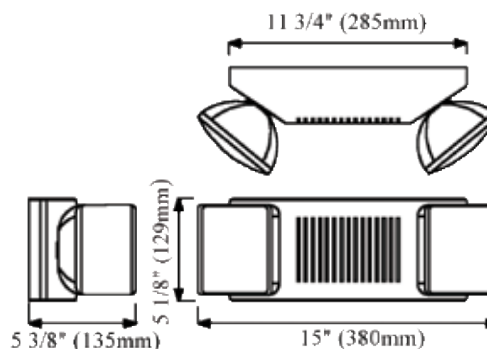

DESCRIPTION

The EM2 is an attractive, emergency lighting unit with soft rounded corners and adjustable square heads.

APPLICATION

Suitable for use in almost any commercial application.

COMPLIANCE

UL924. Life Safety NFPA 101. UL listed for damp location use.

HOUSING

The housing is made of injection molded thermoplastic. It has high impact resistance and is UL94-5V rated.

MOUNTING

The back mounting plate is made of injection molded thermoplastic. It has a molded in universal J-Box mounting pattern and keyhole slots. The main housing snaps on to the back plate for quick and easy installation.

HEADS

Two attractive square shaped heads with rounded corners are adjustable allowing the end user to direct the light where it will be most useful.

ELECTRICAL/BATTERY

- Dual voltage input 120/277 VAC, 60 Hz.
- Maintenance free, Sealed Lead Calcium 6V, 4.0 AH battery with a maximum full recharge time of 24 hours. Minimum 1½ hour emergency operation.
- Low voltage disconnect of the battery prevents deep discharge and maintains good battery life.
- Fully automatic, solid state charger.
- Test switch with LED charge indicator/AC voltage indicator.
- Line Latching feature prevents the unit from turning on during installation to a non-energized AC circuit.