

BMP[®]71 Label Materials

BradyID.com/bmp71

General Identification and Rating Plates (B-424, B-430, B-459, B-483, B-486, B-488, B-489)

Choose from several materials with aggressive adhesives for use in commercial/industrial applications.

- **B-424 Paper Material** - White matte paper material
- **B-430 Polyester Material** - Clear glossy polyester
- **B-459 Polyester Material** - White matte polyester
- **B-483 Polyester Material** - White glossy polyester with an aggressive adhesive
- **B-486 Polyester Material** - Metallized matte polyester
- **B-488 Polyester Material** - White matte polyester with an aggressive adhesive
- **B-489 Polyester Material** - White matte polyester with an aggressive adhesive

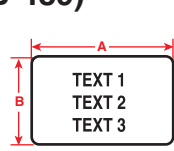


Figure 29

 


Figure 33



Diagram	Catalog #	B#	Material	Color	Label Width A Inch (mm)	Label Height B Inch (mm)	Labels Per Roll	Rec. Ribbon
B-424 Paper Labels								
Fig. 29	BM71-20-424	B-424	Paper	White	2.000 (50.8)	1.000 (25.4)	1000	M71-R4300
Fig. 29	M71-20-424	B-424	Paper	White	2.000 (50.8)	1.000 (25.4)	100	M71-R4300
B-430 Clear Glossy Polyester Labels								
Fig. 29	M71-68-430	B-430	Polyester	Clear	0.240 (6.0)	0.150 (3.8)	750	M71-R6000
Fig. 29	M71-71-430	B-430	Polyester	Clear	0.350 (8.9)	0.200 (5.1)	750	M71-R6000
Fig. 33	M71C-375-430	B-430	Polyester	Clear	0.375 (9.5)	50 ft. (15.2 m)	1 Roll (cont.)	M71-R6000
Fig. 33	M71C-500-430	B-430	Polyester	Clear	0.500 (12.7)	50 ft. (15.2 m)	1 Roll (cont.)	M71-R6000
Fig. 29	M71-16-430	B-430	Polyester	Clear	1.000 (25.4)	0.375 (9.5)	500	M71-R6000
Fig. 29	M71-17-430	B-430	Polyester	Clear	1.000 (25.4)	0.500 (12.7)	500	M71-R6000
Fig. 33	M71C-1000-430	B-430	Polyester	Clear	1.000 (25.4)	50 ft. (15.2 m)	1 Roll (cont.)	M71-R6000
Fig. 29	M71-45-430	B-430	Polyester	Clear	1.050 (38.1)	0.375 (9.5)	500	M71-R6000
Fig. 33	M71C-1900-430	B-430	Polyester	Clear	1.900 (48.3)	50 ft. (15.2 m)	1 Roll (cont.)	M71-R6000
B-459 Matte Polyester Labels								
Fig. 29	M71-29-459	B-459	Polyester	White	1.500 (38.1)	0.500 (12.7)	500	M71-R6000
Fig. 29	M71-30-459	B-459	Polyester	White	1.500 (38.1)	0.750 (19.1)	250	M71-R6000
Fig. 29	M71-20-459	B-459	Polyester	White	2.000 (50.8)	1.000 (25.4)	100	M71-R6000
B-483 Gloss Polyester Labels with an Aggressive Adhesive								
Fig. 33	M71C-500-483	B-483	Polyester	White	0.500 (12.7)	50 ft. (15.2 m)	1 Roll (cont.)	M71-R6000
Fig. 29	M71-16-483	B-483	Polyester	White	1.000 (25.4)	0.375 (9.5)	500	M71-R6000
Fig. 29	M71-17-483	B-483	Polyester	White	1.000 (25.4)	0.500 (12.7)	500	M71-R6000
Fig. 29	M71-19-483	B-483	Polyester	White	1.000 (25.4)	1.000 (25.4)	250	M71-R6000
Fig. 33	M71C-1000-483	B-483	Polyester	White	1.000 (25.4)	50 ft. (15.2 m)	1 Roll (cont.)	M71-R6000
Fig. 29	M71-65-483	B-483	Polyester	White	1.375 (34.9)	1.000 (25.4)	250	M71-R6000
Fig. 29	M71-29-483	B-483	Polyester	White	1.500 (38.1)	0.500 (12.7)	500	M71-R6000
Fig. 29	M71-30-483	B-483	Polyester	White	1.500 (38.1)	0.750 (19.1)	250	M71-R6000
Fig. 29	M71-31-483	B-483	Polyester	White	1.500 (38.1)	1.000 (25.4)	250	M71-R6000
Fig. 33	M71C-1900-483	B-483	Polyester	White	1.900 (48.3)	50 ft. (15.2 m)	1 Roll (cont.)	M71-R6000
Fig. 29	M71-61-483	B-483	Polyester	White	2.000 (50.8)	0.500 (12.7)	100	M71-R6000
Fig. 29	M71-20-483	B-483	Polyester	White	2.000 (50.8)	1.000 (25.4)	100	M71-R6000
Fig. 29	M71-37-483	B-483	Polyester	White	3.000 (76.2)	1.900 (48.3)	100	M71-R6000
Fig. 29	M71-23-483	B-483	Polyester	White	4.000 (101.6)	1.000 (25.4)	100	M71-R6000
Fig. 29	M71-38-483	B-483	Polyester	White	4.000 (101.6)	1.900 (48.3)	100	M71-R6000
B-486 Metallized Polyester Labels with an Aggressive Adhesive								
Fig. 29	M71-17-486	B-486	Polyester	Silver	1.000 (25.4)	0.500 (12.7)	500	M71-R4300
Fig. 29	M71-29-486	B-486	Polyester	Silver	1.500 (38.1)	0.500 (12.7)	500	M71-R4300
Fig. 29	M71-30-486	B-486	Polyester	Silver	1.500 (38.1)	0.750 (19.1)	250	M71-R4300
Fig. 29	M71-20-486	B-486	Polyester	Silver	2.000 (50.8)	1.000 (25.4)	100	M71-R4300
Fig. 29	M71-37-486	B-486	Polyester	Silver	3.000 (76.2)	1.900 (48.3)	100	M71-R4300
B-488 Matte Polyester Labels								
Fig. 29	M71-80-488	B-488	Polyester	White	0.750 (19.1)	0.900 (22.9)	250	M71-R4300
Fig. 29	M71-97-488	B-488	Polyester	White	0.900 (22.9)	0.900 (22.9)	250	M71-R4300
Fig. 29	M71-81-488	B-488	Polyester	White	1.900 (48.3)	0.250 (6.4)	750	M71-R4300
B-489 Matte Polyester Labels with an Aggressive Adhesive								
Fig. 29	M71-29-489	B-489	Polyester	White	1.500 (38.1)	0.500 (12.7)	500	M71-R4300
Fig. 29	M71-32-489	B-489	Polyester	White	1.500 (38.1)	1.500 (38.1)	250	M71-R4300
Fig. 29	M71-38-489	B-489	Polyester	White	4.000 (101.6)	1.900 (48.3)	100	M71-R4300
Fig. 29	M71-17-489	B-489	Polyester	White	1.000 (25.4)	0.500 (12.7)	500	M71-R4300

See all BMP[®]71 Print Ribbon parts on page 337.