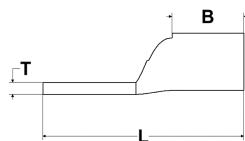



[On Line Catalog](#)


BURNDY Catalog Number	YA6CL1BOX
UPC Number	781810552803
Description	6 STR CU1HLE SHT8-GLOBAL
Status	Active

Web Use
BURNDY Product Line

Tongue Angle	Straight
Strip Length	9/16
Length (in)	1.27
Tongue Type	Standard
Barrell Style	Chamfered,Skived
Barrel Type	Standard
Thickness	0.09
B Length (in)	0.54
Pad Width (in)	0.41

Dimensional

General

1

Copper Compression Lug, 1 Hole
w/ Inspection Window, 6 AWG,
#8-#10 Stud, Short Barrel, Tin
Plated

Number of Holes

Product Description

Conductor(s)

N/A

6 AWG

Copper Solid Size (Range)

Copper Stranded (Range)

Physical

Tin - Electro Plated

Blue

Y

7,374

Copper

Type of Plating

Color Code

Plated (Yes or No)

Index Number

Product Material

Approvals / Certifications

Y

Y

Compliant

N

N

UL Listed

CSA Certified

ROHS Compatible

UL Recognized

CULUS

Documentation

For further technical assistance, please contact us

BURNDY LLC - USA

BURNDY Technical Services

Hours: 8.00 AM - 5.00 PM

Monday - Friday

Phone: 000-346-4175

47, industrial Park Drive
Manchester NH03109

47, industrial Park Drive
Manchester NH03109