


120V LINE VOLTAGE
XENON & HALOGEN

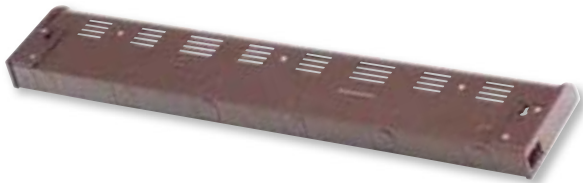

**HARDWIRE,
PORTABLE & LINKABLE
WITH NO ADDITIONAL WIRING MODULES**
(SpeedLink version shown above)



MOUNTING & KNOCKOUTS

Counter Attack installs easily with two easy-to-access mounting screws (provided) in keyhole slots. Fast, easy installation with multiple knockouts on back and top for through-wiring, flex, Romex or rigid conduit.

FEATURES & BENEFITS

Improved CounterAttack


Removable hinged diffuser; easy and safe lamp replacement

Captive screws: Easiest installation for under cabinet lighting

- 120V 35W Halogen and Xenon non-linking versions
- Longer lamp life than others due to patented cooling system
- Fast easy installation – complete with mounting hardware
- Knockouts on ends (non-linking only), back and top for through-wiring, Wiremold, flex, Romex or rigid conduit
- Dimmable with standard **incandescent dimmer**.
- Repositioned cooling slots.
- PORCELAIN SOCKETS used for high temperature durability
- Non-yellowing U.V. coated glass prismatic diffuser for maximum light distribution and U.V. protection
- Lamps included, no tools required for relamping
- Hi-Off-Lo switch, dimmable, energy saving
- Low profile fixture – 1 1/2" high
- Available in white, stainless steel and bronze
- Protected by multiple US patents



Patented baffle increases the velocity of the cooling air.

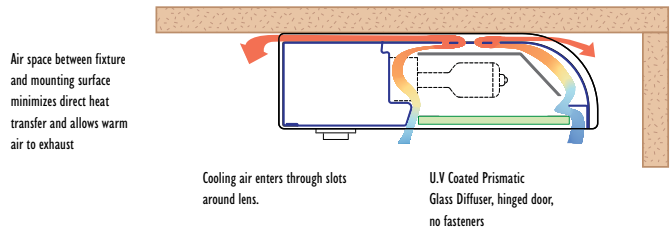

**COUNTER-ATTACK'S PATENTED
COOLEST OPERATING UNDERCABINET SYSTEM**

Cooling air enters through openings at bottom of the fixture, moves through the fixture by convection, to the top of the fixture and out the vents. The unique baffle acts as a heat shield and increases the velocity of the cooling air. Air space above the fixture minimizes direct contact with the mounting surface and allows warm air to exhaust from fixture reducing heat transfer.



Removable hinged diffuser for easy and safe lamp replacement.

Lamp 120V: L-25 35W Halogen Type JCD G-8 Base Clear, 320 lumens, 2,650°K
L-35 35W Xenon Type JCD G-8 Base Clear, 270 lumens, 2,900°K
Finishes WT-White, SS-Stainless Steel, BZ-Bronze



40" 40"L x 5"W x 1 1/2"H



5 Lamp

Voltage / Finish	WT	SS	BZ
120V Halogen	NCA-120-40 WT	NCA-120-40 SS	NCA-120-40 BZ
120V Xenon	NCAX-120-40 WT	NCAX-120-40 SS	NCAX-120-40 BZ

32" 32"L x 5"W x 1 1/2"H



4 Lamp

Voltage / Finish	WT	SS	BZ
120V Halogen	NCA-120-32 WT	NCA-120-32 SS	NCA-120-32 BZ
120V Xenon	NCAX-120-32 WT	NCAX-120-32 SS	NCAX-120-32 BZ
SPEED&LINK 120V Xenon	NCAX120L-32 WT	NCAX120L-32 SS	NCAX120L-32 BZ

24" 24"L x 5"W x 1 1/2"H



3 Lamp

Voltage / Finish	WT	SS	BZ
120V Halogen	NCA-120-24 WT	NCA-120-24 SS	NCA-120-24 BZ
120V Xenon	NCAX-120-24 WT	NCAX-120-24 SS	NCAX-120-24 BZ
SPEED&LINK 120V Xenon	NCAX120L-24 WT	NCAX120L-24 SS	NCAX120L-24 BZ

16" 16"L x 5"W x 1 1/2"H



2 Lamp

Voltage / Finish	WT	SS	BZ
120V Halogen	NCA-120-16 WT	NCA-120-16 SS	NCA-120-16 BZ
120V Xenon	NCAX-120-16 WT	NCAX-120-16 SS	NCAX-120-16 BZ
SPEED&LINK 120V Xenon	NCAX120L-16 WT	NCAX120L-16 SS	NCAX120L-16 BZ

8" 8"L x 5"W x 1 1/2"H



1 Lamp

Voltage / Finish	WT	SS	BZ
120V Halogen	NCA-120-8 WT	NCA-120-8 SS	NCA-120-8 BZ
120V Xenon	NCAX-120-8 WT	NCAX-120-8 SS	NCAX-120-8 BZ
SPEED&LINK 120V Xenon	NCAX120L-8 WT	NCAX120L-8 SS	NCAX120L-8 BZ

SPEED&LINK™



CSL's CounterAttack with SpeedLink™ allows fast and easy linking of multiple units. The system features custom connectors that allow end-to-end mounting with instant electrical connections – no wiring between units. When units are not mounted end-to-end, SpeedLink™ inter-connect cables allow easy and fast linking.

See page 17 for more details about SpeedLink™



Master Switch module (CS-1) controls a run of Counter Attack SpeedLink™ with a single switch. Available in white, stainless steel and bronze.