

Calbrite™

Stainless Steel Conduit Systems

Stainless Steel “Mini” Hangers

Features:

- Manufactured in type 316 stainless steel to meet any stringent sanitary condition
- Polished with standard "brite" finish to increase corrosion resistance and aesthetic appearance
- Designed for use with stainless rigid, stainless IMC, galvanized, & aluminum conduit
- Stainless steel nut & bolt included
- No package qty. required



Certifications and Compliances:


Calbrite stainless steel Conduit Hangers are fabricated to UL standards. Manufactured in the United States.

Applications:

Type 316 stainless steel conduit hangers are great for securing and mounting conduit, tubing, & cable in corrosive environments.

Industries Commonly Served:

- Food & Beverage Production & Distribution
- Chemical Plants
- Water & Wastewater Treatment
- Pharmaceuticals & Cosmetics
- Refining & Extraction Sites
- Petrochemical Operations
- Marine & Coastal Facilities
- Pulp and Paper Mills
- Along with other corrosive environments

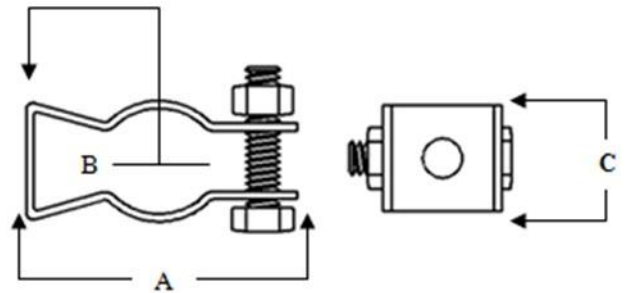

Size	Part Number	A	B	C	Nut & bolt size / Bolt hole size	Wt. per lb.
1/2"	S60500MH00	1.87"	7/8"	0.75"	1/4"	0.04
3/4"	S60700MH00	2.33"	15/16"	.875"	1/4"	0.06
1"	S61000MH00	2.63"	1-1/8"	.875"	1/4"	0.07
1-1/4"	S61200MH00	3.23"	1-3/8"	.875"	1/4"	0.09
1-1/2"	S61500MH00	3.38"	1-7/16"	1.25"	1/4"	0.17
2"	S62000MH00	4.03"	2"	1.25"	1/4"	0.20
2-1/2"	S62500MH00	4.60"	2-1/16"	1.25"	1/4"	0.23
3"	S63000MH00	5.60"	2-11/16"	1.25"	1/4"	0.28
4"	S64000MH00	6.73"	3-3/16"	1.25"	1/4"	0.33

*All dimensions are for informational purposes only *Tolerances +/- 5%*