

Calbrite™

Stainless Steel Conduit Systems

Stainless Steel Cord Grips

Features:

- Manufactured in type 304 stainless steel
- Provides exceptional tensile strength and the highest levels of durability in harsh / corrosive environments
- Polished with standard "brite" finish to increase corrosion resistance and aesthetic appearance
- All connectors include an embedded Buna-A O-Ring
- All connectors include a stainless steel Locknut
- No package qty. required

Certifications and Compliances:


UL 514D Listed
 CSA Certified
 Buy American Compliant
 NEMA 4X Approved

Applications:

Stainless Cord Grips completely eliminate pull tension on terminals, control cable arc-of-bend, prevent cord pull-out, and provide a liquid-tight seal. All connectors can be ordered with or without wire mesh attachments and accommodate conduit sizes from 1/2" to 2"

Industries Commonly Served:

- Food & Beverage Production & Distribution
- Chemical Plants
- Water & Wastewater Treatment
- Pharmaceuticals & Cosmetics
- Refining & Extraction Sites
- Petrochemical Operations
- Marine & Coastal Facilities
- Pulp and Paper Mills
- Along with other corrosive environments

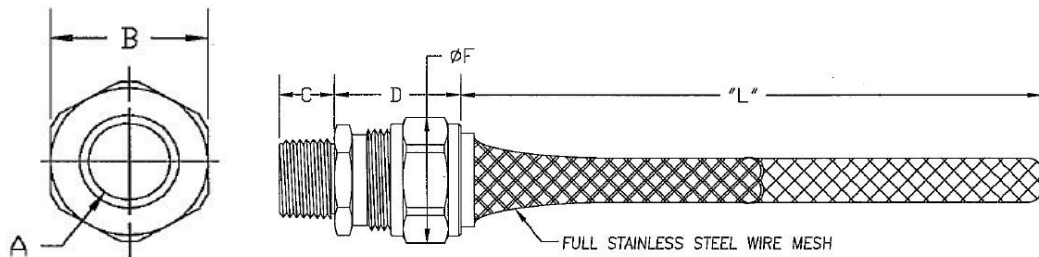

Size	A (Body Bore)	B	C	D	L (Range)	F (Nut Dia.)
1/2"	0.610"	1.250"	0.540"	1.270"	8-3/4" - 11-1/2"	1.520"
3/4"	0.810"	1.250"	0.560"	0.960"	8-3/4" - 11-1/2"	1.520"
1"	0.990"	1.750"	0.570"	1.460"	13-1/4" - 14-1/2"	1.720"
1-1/2"	1.430"	2.250"	0.690"	1.810"	13-1/4" - 14-1/2"	2.470"
2"	2.000"	2.830"	0.800"	2.320"	14-3/4" - 16-3/4"	2.970"

All dimensions are for informational purposes only *Tolerances +/- .5