

Calbrite™

Stainless Steel Conduit Systems

Stainless Steel U-Bolts

Features:

- Manufactured in type 316 stainless steel for increased corrosion resistance
- Polished with standard "brite" finish to increase corrosion resistance and aesthetic appearance
- Figure 137 style
- Four type 316 stainless steel hex nuts included
- No package qty. required



Certifications and Compliances:


Calbrite stainless steel U-Bolts are fabricated to UL & ASTM F593 standards.

Applications:

Used to mount & secure electrical conduit.

Industries Commonly Served:

- Food & Beverage Production & Distribution
- Chemical Plants
- Water & Wastewater Treatment
- Pharmaceuticals & Cosmetics
- Refining & Extraction Sites
- Petrochemical Operations
- Marine & Coastal Facilities
- Pulp and Paper Mills
- Along with other corrosive environments

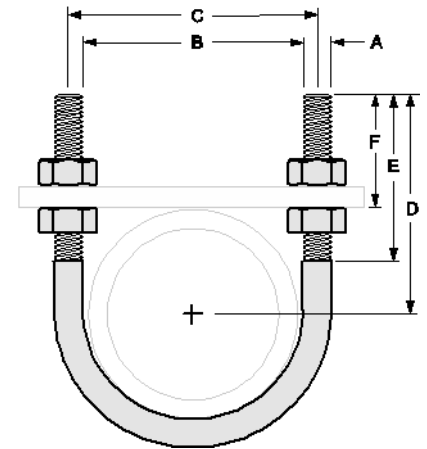

Size	Part Number	A	B	C	D	E	F	Weight per 100 (lb.)
1/2"	S60500UB00	1/4"	0.950	1.400"	2.750"	2.250"	2.313"	10
3/4"	S60700UB00	1/4"	1.250"	1.650"	2.500"	2.250"	2.219"	11
1"	S61000UB00	1/4"	1.375"	1.825"	2.750"	2.500"	2.094"	12
1-1/4"	S61200UB00	3/8"	1.750"	2.350"	3.000"	2.500"	2.031"	28
1-1/2"	S61500UB00	3/8"	2.000"	2.700"	3.000"	2.500"	2.063"	29
2"	S62000UB00	3/8"	2.438"	2.813"	3.250"	2.500"	2.063"	32
2-1/2"	S62500UB00	1/2"	3.000"	3.875"	3.750"	3.000"	2.250"	73
3"	S63000UB00	1/2"	3.650"	4.500"	4.000"	3.000"	2.250"	79
3-1/2"	S63500UB00	1/2"	4.063"	4.563"	4.250"	3.000"	2.250"	82
4"	S64000UB00	1/2"	4.500"	5.375"	4.750"	3.000"	2.250"	50

All dimensions are for informational purposes only *Tolerances +/-5%