



STAINLESS STEEL EXPLOSION PROOF (Type 316SS)



EYS Explosion Proof Sealing Fitting

Trade Size	Part Number
¾"	S60700EYSO






GUAT Explosion Proof Outlet Box

Trade Size	Part Number
¾"	S60700GUAT





UNY Explosion Proof Union


Trade Size	Part Number
¾"	S60700UNYO



STAINLESS STEEL COUPLINGS

Standard Couplings (Type 316SS)

Trade Size	Metric Size	Wt. (lbs)	A	Part Number
½"	16	0.17	1.570"	S60500CP00
¾"	21	0.29	1.630"	S60700CP00
1"	27	0.34	2.000"	S61000CP00
1-¼"	35	0.51	2.050"	S61200CP00
1-½"	41	0.61	2.063"	S61500CP00
2"	53	0.90	2.125"	S62000CP00
2-½"	63	1.87	3.190"	S62500CP00
3"	78	1.93	3.250"	S63000CP00
4"	103	3.97	3.540"	S64000CP00
5"	129	5.96	3.970"	S65000CP00
6"	155	9.94	4.270"	S66000CP00

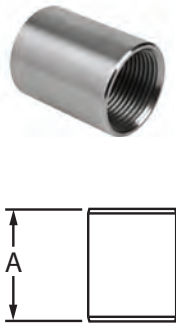

STAINLESS STEEL 3-PIECE COUPLINGS

3-Piece Couplings (Union) (Type 316SS)

Trade Size	Metric Size	Wt. (lbs)	Part Number
½"	16	0.44	S605003U00
¾"	21	0.58	S607003U00
1"	27	0.94	S610003U00
1-¼"	35	1.19	S612003U00
1-½"	41	1.47	S615003U00
2"	53	2.27	S620003U00
2-½"	63	3.09	S625003U00
3"	78	2.50	S630003U00
4"	103	6.44	S640003U00



STAINLESS STEEL LINE TERMINATOR HUBS

LT Hubs (Type 316SS)

Trade Size	Metric	Wt. (lbs)	Part Number
½"	16	0.19	S60500LT00
¾"	21	0.25	S60700LT00
1"	27	0.45	S61000LT00
1-¼"	35	0.67	S61200LT00
1-½"	41	0.72	S61500LT00
2"	53	1.08	S62000LT00
2-½"	63	1.91	S62500LT00
3"	78	2.43	S63000LT00
4"	103	4.09	S64000LT00



STAINLESS STEEL GROUNDING HUBS

Grounding Hubs (Type 316SS)

Trade Size	Metric	Wt. (lbs)	Part Number
½"	16	0.40	S60500LTV2
¾"	21	0.54	S60700LTV2
1"	27	0.75	S61000LTV2
1-¼"	35	1.00	S61200LTV2
1-½"	41	1.16	S61500LTV2
2"	53	1.62	S62000LTV2
2-½"	63	2.85	S62500LTV2
3"	78	3.81	S63000LTV2
4"	103	5.35	S64000LTV2

