

Presented By: Candela Corporation
Contact Phone: (800) 922-9226
Contact E-mail: sales@candelacorp.com


Customer Name:
Project Name:
Fixture Type:



GE
Lighting

17522 - 100A/RS 60PK

GE A21 - Rough Service

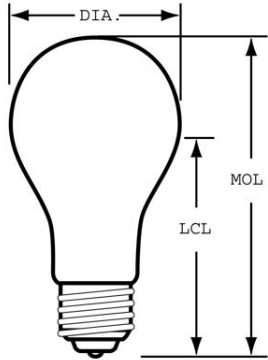

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - A-line
Bulb	A21
Base	Medium Screw (E26)
Filament	C-17
Bulb Finish	Inside frost
Wattage	100/89
Voltage	130/120
Rated Life	1000 hrs
Bulb Material	Soft glass
Primary Application	Rough Service

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	1060 /800
Nominal Initial Lumens per Watt	10 /8

DIMENSIONS

Maximum Overall Length (MOL)	5.25 cm
Bulb Diameter (DIA)	2.625 cm
Bulb Diameter (DIA) (MAX)	2.625 cm
Light Center Length (LCL)	3.81 cm

PRODUCT INFORMATION

Product Code	17522
Description	100A/RS 60PK
Standard Package	Case
Standard Package GTIN	10043168175224
Standard Package Quantity	60
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	60
UPC	043168175227

CAUTIONS & WARNINGS

Warning

- Unexpected lamp rupture may cause injury, fire, or property damage
 - Avoid direct water/liquid contact.
- Risk of Fire
 - Keep combustible materials away from lamp.

