



WORLDWIDE PARTNER

Commercial Products &amp; Solutions

 [site search](#)
[home](#)[products](#)[education / resources](#)[lighting applications](#)
[Where to Buy](#) | [FAQs](#) | [Contact Us](#) | [EliteNet](#)
[Products](#) > 26370**26370 – 150PAR/FL/STG**

GE covRguard® PAR38 - Shatter-Resistant

- Coating is shatter and weather-resistant. Resists breakage from heat and thermal shock that can occur from water, sleet, snow, molten solder, and weld spatter. Rough service version available for extra tough conditions.

**GENERAL CHARACTERISTICS**

Lamp type	Sealed Beam - PAR
Bulb	PAR38
Base	Medium Skirt (E26/50x39)
Filament	CC-6
Product Technology	Incandescent
Wattage	150
Voltage	120
Rated Life	2000 hrs
Primary Application	Shatter-Resistant

**PHOTOMETRIC CHARACTERISTICS**


Initial Lumens	1700
Nominal Initial Lumens per Watt	11

**DIMENSIONS**

Maximum Overall Length (MOL)	5.3100 in (134.8 mm)
Bulb Diameter (DIA)	4.750 in (120.6 mm)

**PRODUCT INFORMATION**

Product Code	26370
Description	150PAR/FL/STG
Standard Package Case	
Standard Package GTIN	10043168263709
Standard Package Quantity	12
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	12
UPC	043168263702

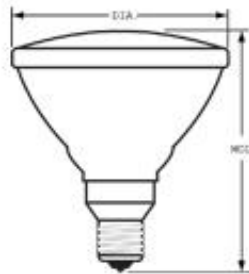


Bulb



Base



Filament

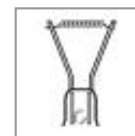[View Larger](#)**ADDITIONAL RESOURCES**[Catalogs](#)[MSDS \(Material Safety Data Sheets\)](#)[Disposal Policies & Recycling Information](#)

## CAUTIONS & WARNINGS

---

[See list of cautions & warnings.](#)

---

## NOTES

---

- Will operate in any burning position, but fixed-socket usage other than base up or continuous burning in any position in ambient temperatures above 150 degrees F (66 degrees C), may result in some loss of protective coating. Reflectors and accessories may raise bulb temperature and cause some loss of protective coating.
- 

[Return To Top](#)

---

[Home](#) | [Products](#) | [EliteNet](#) | [Education/Resources](#) | [Lighting Applications](#) | [Where to Buy](#) | [FAQs](#) | [Contact Us](#) | [Site Map](#)  
[Products for Your Home](#) | [Press Room](#) | [Corporate](#) | [Investor Information](#) | [Privacy Policy](#) | [Accessibility Statement](#) | [Terms of Use](#)

Copyright General Electric Company 1997-2009