

Presented By: Candela Corporation
Contact Phone: (800) 922-9226
Contact E-mail: sales@candelacorp.com



Customer Name:
Project Name:
Fixture Type:



26371 - 150PAR/SP/STG

GE covRguard® PAR38 - Shatter-Resistant

• Coating is shatter and weather-resistant. Resists breakage from heat and thermal shock that can occur from water, sleet, snow, molten solder, and weld spatter. Rough service version available for extra tough conditions.

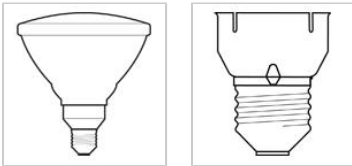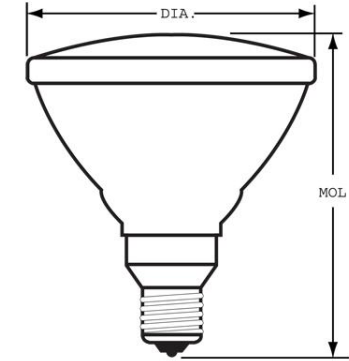

GENERAL CHARACTERISTICS

Lamp Type	Sealed Beam - PAR
Bulb	PAR38
Base	Medium Skirt (E26/50x39)
Filament	CC-6
Wattage	150
Voltage	120
Rated Life	2000 hrs
Primary Application	Shatter-Resistant

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	1700
Nominal Initial Lumens per Watt	11

DIMENSIONS

Maximum Overall Length (MOL)	5.3100 in(134.9 mm)
Bulb Diameter (DIA)	4.750 in(120.6 mm)
Bulb Diameter (DIA) (MAX)	4.750 in(120.6 mm)

PRODUCT INFORMATION

Product Code	26371
Description	150PAR/SP/STG
Standard Package	Case
Standard Package GTIN	10043168263716
Standard Package Quantity	12
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	12
UPC	043168263719

CAUTIONS & WARNINGS

Warning

- Risk of Electric Shock
 - Turn power off before inspection, installation or removal.
- Risk of Fire
 - Keep combustible materials away from lamp.
 - Use in fixture rated for this product.

NOTES

- Will operate in any burning position, but fixed-socket usage other than base up or continuous burning in any position in ambient temperatures above 150 degrees F (66 degrees C), may result in some loss of protective coating. Reflectors and accessories may