



WORLDWIDE PARTNER

[site search](#)[home](#)[products](#)[education / resources](#)

Commercial Products & Solutions

[lighting applications](#)[Where to Buy](#) | [FAQs](#) | [Contact Us](#) | [EliteNet](#)[Products](#) > 28662**28662 – 386**

GE T1.75 (T1 3/4) - Low Voltage

GENERAL CHARACTERISTICS

Lamp type	Miniature - T & TL Shape
Bulb	T1.75 (T1 3/4)
Base	Midget Grooved
Filament	C-2F
Wattage	1
Voltage	14
Rated Life	40000 hrs
Atmosphere	Vacuum
Primary Application	Low Voltage

PHOTOMETRIC CHARACTERISTICS


Initial Lumens	4
Nominal Initial Lumens per Watt	4
Mean Spherical Candlepower (MSCP)	0.3

DIMENSIONS

Maximum Overall Length (MOL)	0.6300 in (16.0 mm)
Bulb Diameter (DIA)	0.219 in (5.5 mm)
Light Center Length (LCL)	0.380 in (9.6 mm)

PRODUCT INFORMATION

Product Code	28662
Description	386
ANSI Code	386
Standard Package	Case
Standard Package GTIN	20043168286620
Standard Package Quantity	50
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	50
UPC	043168286626

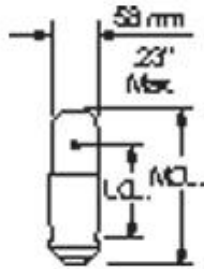

Bulb



Base



Filament

[View Larger](#)**ADDITIONAL RESOURCES**[Catalogs](#)[Disposal Policies & Recycling Information](#)[Return To Top](#)

[Home](#) | [Products](#) | [EliteNet](#) | [Education/Resources](#) | [Lighting Applications](#) | [Where to Buy](#) | [FAQs](#) | [Contact Us](#) | [Site Map](#)
[Products for Your Home](#) | [Press Room](#) | [Corporate](#) | [Investor Information](#) | [Privacy Policy](#) | [Accessibility Statement](#) | [Terms of Use](#)

Copyright General Electric Company 1997-2009