

Presented By: Candela Corporation
Contact Phone: (800) 922-9226
Contact E-mail: sales@candelacorp.com



Customer Name:
Project Name:
Fixture Type:



GE
Lighting

14791 - 25T7N

GE Appliance Light T7 - Appliance

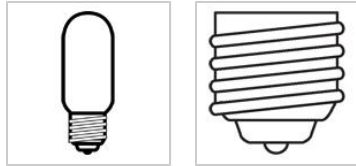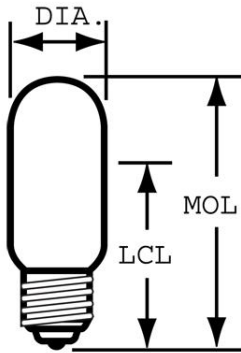

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - Tubular
Bulb	T7
Base	Intermediate Screw (E17)
Filament	C-7A
Bulb Finish	Clear
Wattage	25
Voltage	120
Rated Life	1000 hrs
Bulb Material	Soft glass
Primary Application	Standard;Standard;Appliance

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	7.8 /195 /195
Nominal Initial Lumens per Watt	7

DIMENSIONS

Maximum Overall Length (MOL)	2.25 cm
Bulb Diameter (DIA)	0.875 cm
Bulb Diameter (DIA) (MAX)	0.875 cm
Light Center Length (LCL)	1.56 cm

PRODUCT INFORMATION

Product Code	14791
Description	25T7N
Standard Package	Case
Standard Package GTIN	00043168147910
Standard Package Quantity	60
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	60
UPC	043168904667