



**Presented By:** Candela Corporation  
Contact Phone: (800) 922-9226  
Contact E-mail: sales@candelacorp.com

Customer Name:  
Project Name:  
Fixture Type:



GE  
Lighting

**24448 - 4411**  
GE PAR36 - Tractor

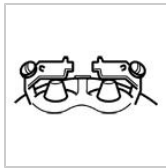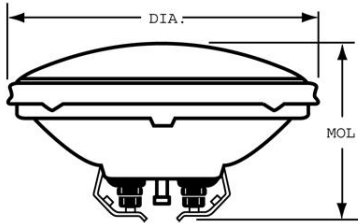

#### GENERAL CHARACTERISTICS

Lamp Type	Sealed Beam - PAR
Bulb	PAR36
Base	Screw Terminals
Filament	C-6
Wattage	35
Voltage	12.8/35
Rated Life	300 hrs
Primary Application	Tractor

#### PHOTOMETRIC CHARACTERISTICS

Beam Spread - Vertical	300.0 - 10.0 °
Beam Spread (10% hor)	Trapezoidal
Abstract Values	
Max. Beam Candlepower (MBCP)	3000

#### DIMENSIONS

Maximum Overall Length (MOL)	2.7500 in(69.8 mm)
Bulb Diameter (DIA)	4.500 in(114.3 mm)
Bulb Diameter (DIA) (MAX)	4.500 in(114.3 mm)

#### PRODUCT INFORMATION

Product Code	24448
Description	4411
ANSI Code	4411
Standard Package	Case
Standard Package GTIN	10043168244487
Standard Package Quantity	12
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	12
UPC	043168244480