

Presented By: Candela Corporation
Contact Phone: (800) 922-9226
Contact E-mail: sales@candelacorp.com


 

Customer Name:
Project Name:
Fixture Type:



GE
Lighting

18518 - 4652

GE 165mm - Automotive

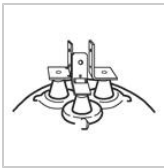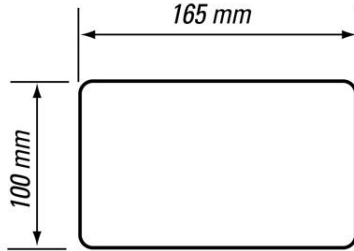

GENERAL CHARACTERISTICS

Lamp Type	Sealed Beam - Rectangular
Bulb	165mm
Base	3 Contact Lugs
Filament	C-6/C-6
Wattage	40/60
Voltage	12.8/12.8001
Rated Life	200 hrs
Bulb Material	Borosilicate glass
Primary Application	Headlamp-Low beam only

PHOTOMETRIC CHARACTERISTICS

Max. Beam Candlepower (MBCP) Abstract Values	SAE specifications
---	--------------------

DIMENSIONS

Maximum Overall Length (MOL)	4.8 cm
---------------------------------	--------

PRODUCT INFORMATION

Product Code	18518
Description	4652
ANSI Code	4652
Standard Package	Case
Standard Package GTIN	00043168185189
Standard Package Quantity	6
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	6
UPC	043168960045

CAUTIONS & WARNINGS

Warning

- Pressurized lamp--unexpected rupture may cause injury, fire, or property damage
 - Dispose of lamp in a closed container.
 - Do not use lamp if outer glass is scratched or broken.