



GE
Lighting

WORLDWIDE PARTNER

[site search](#)

[home](#)

[products](#)

[education / resources](#)

Commercial Products & Solutions

[lighting applications](#)

[Where to Buy](#) | [FAQs](#) | [Contact Us](#) | [EliteNet](#)

[Products](#) > 39906

39906 – 4700

GE PAR36 - Medium Flood; Narrow Spot

GENERAL CHARACTERISTICS

Lamp type	Sealed Beam - PAR
Bulb	PAR36
Base	3 Screw Terminals
Filament	C-6/C-6
Product Technology	Incandescent
Wattage	100/100.001
Voltage	13/13.001
Rated Life	25 hrs
Primary Application	Medium Flood; Narrow Spot

PHOTOMETRIC CHARACTERISTICS

Beam Spread - Horizontal	12° - 10 %, 17° - 10 %
Beam Spread - Vertical	7° - 10 %, 18° - 10 %
Max. Beam	0
Candlepower (MBCP) (MAX)	

DIMENSIONS


Maximum Overall Length (MOL)	2.7500 in (69.8 mm)
Bulb Diameter (DIA)	4.500 in (114.3 mm)

PRODUCT INFORMATION

Product Code	39906
Description	4700
ANSI Code	4700
Standard Package Case	
Standard Package GTIN	00043168399067
Standard Package Quantity	12
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	12
UPC	043168961943



Base

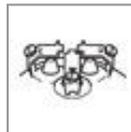

Filament



[View Larger](#)

ADDITIONAL RESOURCES

[Catalogs](#)

[Disposal Policies & Recycling Information](#)

ALSO AVAILABLE IN...

Product Code	Description	Standard Package
39907	4700 BULK	Case

[Home](#) | [Products](#) | [EliteNet](#) | [Education/Resources](#) | [Lighting Applications](#) | [Where to Buy](#) | [FAQs](#) | [Contact Us](#) | [Site Map](#)
[Products for Your Home](#) | [Press Room](#) | [Corporate](#) | [Investor Information](#) | [Privacy Policy](#) | [Accessibility Statement](#) | [Terms of Use](#)

Copyright General Electric Company 1997-2009