

Presented By: Candela Corporation
Contact Phone: (800) 922-9226
Contact E-mail: sales@candelacorp.com

Customer Name:
Project Name:
Fixture Type:






GE
Lighting

35154 - 15T7DC CARD

GE Appliance Light T7 - Vacuum Cleaner; Appliance; Sewing Machine

- GE's specialty bulbs offer innovative solutions for a variety of lighting needs.
- Be sure to check appliances for correct bulb wattage, voltage and base type.

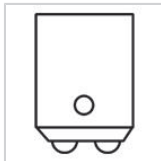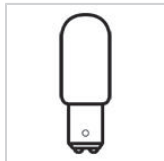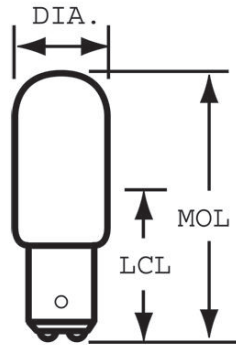

GENERAL CHARACTERISTICS

Lamp Type	Incandescent - Tubular
Bulb	T7
Base	Double Contact Bayonet (BA15d)
Filament	C-7A
Bulb Finish	Clear
Wattage	15
Voltage	120
Bulb Material	Soft glass
Primary Application	Vacuum Cleaner; Appliance; Sewing Machine; Standard; Standard

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	108
Nominal Initial Lumens per Watt	7

DIMENSIONS

Maximum Overall Length (MOL)	2.2500 in(57.2 mm)
Bulb Diameter (DIA)	0.875 in(22.2 mm)
Bulb Diameter (DIA) (MAX)	0.875 in(22.2 mm)
Light Center Length (LCL)	1.310 in(33.3 mm)

PRODUCT INFORMATION

Product Code	35154
Description	15T7DC CARD
Standard Package	Master
Standard Package GTIN	10043168351543
Standard Package Quantity	240
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	240
UPC	043168907057