

Presented By: Candela Corporation
Contact Phone: (800) 922-9226
Contact E-mail: sales@candelacorp.com

Customer Name:
Project Name:
Fixture Type:





GE
Lighting

18274 - 75A/RS 12PK-5

GE Rough Service Worklight A21 - Rough Service

- GE's specialty bulbs offer innovative solutions for a variety of lighting needs.
- The GE Rough Service Worklight is specially designed with rugged filaments and mounts to withstand rough handling and shock better than regular household bulbs.

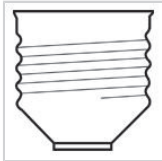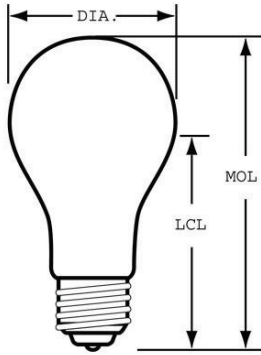

GENERAL CHARACTERISTICS

| | |
|---------------------|-----------------------|
| Lamp Type | Incandescent - A-line |
| Bulb | A21 |
| Base | Medium Screw (E26) |
| Filament | C-17 |
| Bulb Finish | Inside frost |
| Wattage | 75 |
| Voltage | 120 |
| Rated Life | 1000 hrs |
| Bulb Material | Soft glass |
| Primary Application | Rough Service |

PHOTOMETRIC CHARACTERISTICS

| | |
|---------------------------------|---------------|
| Initial Lumens | 750 |
| Beam Spread - Vertical | 35.0 - 50.0 ° |
| Nominal Initial Lumens per Watt | 10 |

DIMENSIONS

| | |
|------------------------------|----------|
| Maximum Overall Length (MOL) | 5.25 cm |
| Bulb Diameter (DIA) | 2.625 cm |
| Bulb Diameter (DIA) (MAX) | 2.625 cm |
| Light Center Length (LCL) | 3.81 cm |

PRODUCT INFORMATION

| | |
|----------------------------------|----------------|
| Product Code | 18274 |
| Description | 75A/RS 12PK-5 |
| Standard Package | BUNDLE |
| Standard Package GTIN | 00043168182744 |
| Standard Package Quantity | 60 |
| Sales Unit | Unit |
| No Of Items Per Sales Unit | 1 |
| No Of Items Per Standard Package | 60 |
| UPC | 043168904117 |

CAUTIONS & WARNINGS

Warning

- Unexpected lamp rupture may cause injury, fire, or property damage
 - Avoid direct water/liquid contact.
- Risk of Fire
 - Keep combustible materials away from lamp.