

Miniature Lamp Specifications

Line No.	Lamp No.	Base	Des. Volts	Amps or Watts	MSCP	Fil. Type	MOL (inch)	LCL (inch)	Ave Life (Hrs)	Primary Application	Fig. No.
T-1 Bulb											
1	6832	Wire Terminals (Short)	5.0	.06	.05	C-2R	.145	-	100,000	Aircraft	23
2	683	Wire Terminals (Standard)	5.0	.06	.05	C-2R	.250	-	100,000	Aircraft	24
3	8111	Wire Terminals (Standard)	14.0	.065	.150	C-2F	.250	-	16,000	Indicator	24
4	6838	Wire Terminals (Standard)	28.0	.024	.150	CC-2F	.250	-	16,000	Aircraft	24
5	7154AS15	Axial Leads	5.0	.115	.15	C-8	.35	-	40,000	Indicator	25
6	6839	Sub-Midget Flanged	28.0	.024	.150	CC-2F	.375	-	16,000	Aircraft	26
7	7839	Bipin	28.0	.024	.150	CC-2F	.63	-	16,000	Aircraft	27
T-1 1/2 Bulb											
8	E79	Subminiature Wedge	6.0	.20	.60	C-2R	-	-	1,000	Indicator	-
9	E86	Subminiature Wedge	6.3	.20	.40	C-2F	-	-	20,000	Indicator	-
10	E73	Subminiature Wedge	14.0	.08	.30	C-2F	-	-	15,000	Auto	-
11	E37	Subminiature Wedge	14.0	.09	.50	C-2F	-	-	2,500	Auto	-
12	E74	Subminiature Wedge	14.0	.10	.70	C-2F	-	-	500	Auto	-
13	E85	Subminiature Wedge	28.0	.04	.30	C-2F	-	-	7,000	Indicator	-
14	E17	Subminiature Wedge	28.0	.065	.65	C-2F	-	-	5,000	Indicator	-
T-1 3/4 Bulb											
15	1767	Midget Screw	2.5	.20	.20	C-2R	.63	.52	500	Toy	29
16	338	S.C. Midget Flanged	2.7	.06	.04	C-2R	.63	.38	6,000	Indicator	30
17	345	S.C. Midget Flanged	6.0	.04	.03	C-2V	.63	.38	10,000	Indicator	30
18	328	S.C. Midget Flanged	6.0	.20	.34	C-2R	.63	.38	1,000	Aircraft	30
19	79	Subminiature Wedge	6.0	.20	.60	C-2R	.80	.40	1,000	Indicator	31
20	7381	Bipin	6.3	.20	.40	C-2V	.66	.50	20,000	PC Boards	28
21	86	Subminiature Wedge	6.3	.20	.40	C-2F	.80	.40	20,000	Indicator	31
22	379	Midget Grooved	6.3	.20	.40	C-2V	.63	.38	20,000	Indicator	32
23	381	S.C. Midget Flanged	6.3	.20	.40	C-2V	.63	.38	20,000	Indicator	30
24	367	S.C. Midget Flanged	10.0	.04	.08	C-2F	.63	.38	5,000	Indicator	30
25	73	Subminiature Wedge	14.0	.08	.30	C-2F	.80	.40	15,000	Auto	31
26	330	S.C. Midget Flanged	14.0	.08	.50	C-2F	.63	.38	1,500	Aircraft	30
27	382	S.C. Midget Flanged	14.0	.08	.30	C-2F	.63	.38	15,000	Indicator	30
28	2182D	Wire Terminal	14.0	.08	.30	C-2F	-	-	40,000	Indicator	-
29	386	Midget Grooved	14.0	.08	.30	C-2F	.63	.38	40,000	Indicator	32
30	37	Subminiature Wedge	14.0	.09	.50	C-2F	.80	.40	2,500	Auto	31

 


Fig. 23



Fig. 24

 


Fig. 25



Fig. 26



Fig. 27

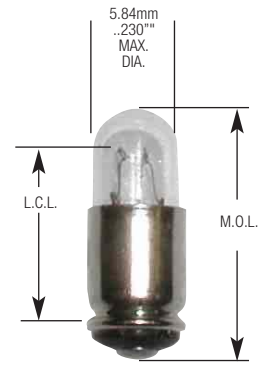
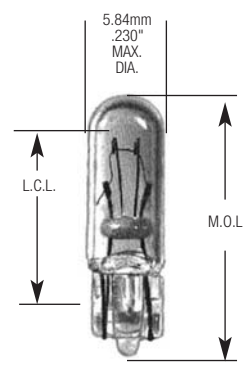
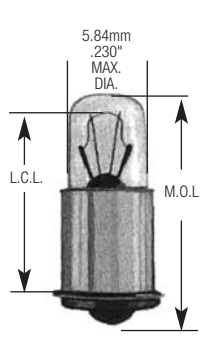
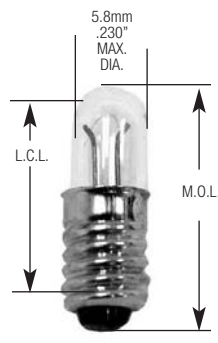
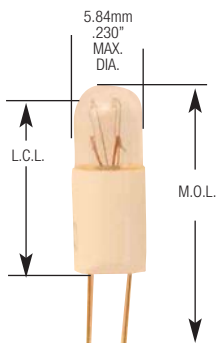


Fig. 28 (C-2V filament shown) Fig. 29 (C-2R filament shown) Fig. 30 (C-2F filament shown) Fig. 31 (C-2F filament shown) Fig. 32 (C-2F filament shown)

Some lamp pictures are not to scale. Filament and L.C.L. may vary by part number. For filament identification see page 6.

THE PRODUCTS SHOWN REPRESENT ONLY A SMALL PORTION OF OUR STOCK
PLEASE CALL IF THE PRODUCT YOU NEED IS NOT LISTED
949/452-0900 • 800/8-LIGHTS • FAX: 800-255-3141

Miniature Lamp Specifications

Line No.	Lamp No.	Base	Des. Volts	Amps or Watts	MSCP	Fil. Type	MOL (inch)	LCL (inch)	Ave Life (Hrs)	Primary Application	Fig. No.
T-1 3/4 Bulb (Continued)											
1	74	Subminiature Wedge	14.0	.10	.70	C-2F	.80	.40	500	Auto	31
2	7373	Bipin	14.0	.10	.50	C-2F	.66	.50	10,000	PC Boards	28
3	7387	Bipin	28.0	.04	.30	C-2F	.66	.50	7,000	Indicator	28
4	70	Subminiature Wedge	14.0	.15	1.5	C-2F	.63	.40	100	Auto	31
5	2187D	Wire Terminal	28.0	.04	.30	C-2F	-	-	1,000	Indicator	-
6	85	Subminiature Wedge	28.0	.04	.30	C-2F	.80	.40	7,000	Indicator	31
7	320A	Special Thread	28.0	.04	-	C-2F	-	-	1,000	Amber, Aircraft	-
8	385	S.C. Midget Flanged	28.0	.04	.15	C-2F	.63	.38	10,000	Indicator	30
9	387	S.C. Midget Flanged	28.0	.04	.30	C-2F	.63	.38	7,000	Indicator	30
10	388	Midget Grooved	28.0	.04	.30	C-2F	.63	.38	7,000	Indicator	32
11	327	S.C. Midget Flanged	28.0	.04	.34	C-2F	.63	.38	4,000	Aircraft	30
12	334	Midget Grooved	28.0	.04	.34	C-2F	.63	.38	4,000	Aircraft	32
13	335	Midget Screw	28.0	.04	.34	C-2F	.72	.52	4,000	Indicator	29
14	17	Subminiature Wedge	28.0	.065	.65	C-2F	.80	.40	5,000	Indicator	31

T-2 Bulb											
15	6PSB	Slide No. 5	6.0	.14	2550	C-2F	1.12	-	20,000	Indicator	33
16	12PSB	Slide No. 5	12.0	.17	2000	C-2F	1.12	-	12,000	Indicator	33
17	24E	Slide No. 3	24.0	.035	600	C-2F	1.69	-	7,000	Telephone	34
18	24E1	Slide No. 3	24.0	.035	450	C-2F	1.69	-	5,000	Telephone	34
19	24E2	Slide No. 2	24.0	.03	600	C-2F	1.69	-	8,000	Indicator	34
20	24PSB	Slide No. 5	24.0	.073	3000	C-2F	1.12	-	10,000	Indicator	33
21	24X	Special Slide No. 2	24.0	.035	600	C-2F	1.69	-	8,000	Special Telephone	-
22	28PSB	Slide No. 5	28.0	.04	1600	C-2F	1.12	-	5,000	Indicator	33
23	48PSB	Slide No. 5	48.0	.05	1800	C-7A	1.12	-	10,000	Indicator	33
24	60PSB	Slide No. 5	60.0	.05	2200	C-7A	1.12	-	7,500	Indicator	33
25	120PSB	Slide No. 5	120.0	.025	1200	CC-7A	1.12	-	7,500	Indicator	33
26	155PSB	Slide No. 5	155.0	.025	1200	CC-7A	1.12	-	10,000	Indicator	33

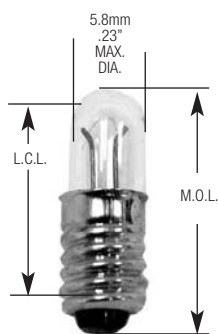


Fig. 29 (C-2R filament shown)

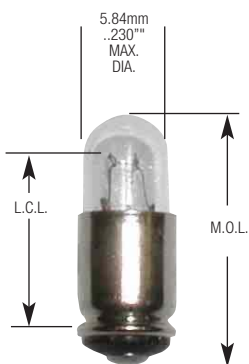


Fig. 32 (C-2F filament shown)

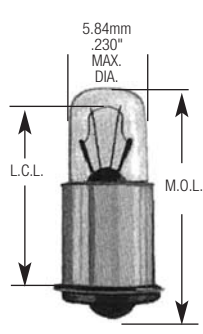


Fig. 30 (C-2F filament shown)

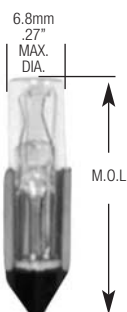


Fig. 33 (C-2F filament shown)

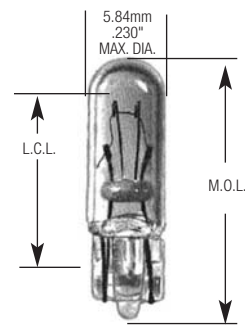


Fig. 31 (C-2F filament shown)

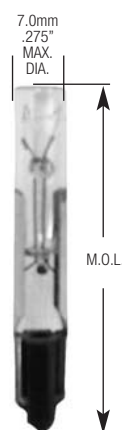



Fig. 34 (C-2F filament shown)

Some lamp pictures are not to scale. Filament and L.C.L. may vary by part number. For filament identification see page 6.

THE PRODUCTS SHOWN REPRESENT ONLY A SMALL PORTION OF OUR STOCK
PLEASE CALL IF THE PRODUCT YOU NEED IS NOT LISTED
949/452-0900 • 800/8-LIGHTS • FAX: 800-255-3141

Miniature Lamp Specifications

Line No.	Lamp No.	Base	Des. Volts	Amps or Watts	MSCP	Fil. Type	MOL (inch)	LCL (inch)	Ave Life (Hrs)	Primary Application	Fig. No.
T-2 1/2 Bulb											
1	6MB	Miniature Bayonet	6.0	.14	.12	C-2F	1.19	.95	20,000	Indicator	35
2	12MB	Miniature Bayonet	12.0	.17	.35	C-2F	1.19	.95	12,000	Indicator	35
3	24MB	Miniature Bayonet	24.0	.07	.50	C-2F	1.19	.95	10,000	Indicator	35
4	28MB	Miniature Bayonet	28.0	.05	.29	C-2F	1.19	.95	5,000	Indicator	35
5	48MB	Miniature Bayonet	48.0	.05	.70	C-7A	1.19	.95	10,000	Indicator	35
6	60MB	Miniature Bayonet	60.0	.05	.73	C-7A	1.19	.95	7,500	Indicator	35
7	90MB	Miniature Bayonet	90.0	.03	.37	CC-7A	1.19	.95	5,000	Indicator	35
8	120MB	Miniature Bayonet	120.0	.025	.36	CC-7A	1.19	.95	10,000	Indicator	35
9	130MB	Miniature Bayonet	130.0	.025	.36	CC-7A	1.19	.95	10,000	Indicator	35
10	155MB	Miniature Bayonet	155.0	.025	.36	CC-7A	1.19	.95	10,000	Indicator	35
T-3 Bulb											
11	561	Rigid Loop	12.8	.97	12	C-8	1.72	-	1,000	Auto-Dome	36
12	563	Rigid Loop	13.5	.52	4	C-8	1.72	-	1,000	Auto-Dome	36
13	211-2	End Caps	12.8	.97	12	C-8	1.72	-	1,000	Auto	37
14	212-2	End Caps	13.5	.74	6	C-8	1.72	-	2,000	Auto	37
15	562	Rigid Loop	13.5	.74	6	C-8	1.72	-	2,000	Auto-Interior	36
16	564	Rigid Loop	14.0	.44	2	C-8	1.72	-	7,500	Auto-Interior	36
17	1477	Miniature Screw	24.0	.17	3.3	C-2V	1.25	.81	250	Indicator	38
T-3 1/4 Bulb											
18	1490	Miniature Bayonet	3.2	.16	.20	C-2R	1.19	.71	3,000	Radio	39
19	45	Miniature Bayonet	3.2	.35	.50	C-2R	1.19	.71	3,000	Radio	39
20	1906	Miniature Bayonet	5.0	.07	.19	C-6	1.19	.63	1,000	Signal	39
21	285	Wedge	5.0	.09	.25	C-2R	1.06	.56	1,500	Signal	40
22	1850	Miniature Bayonet	5.0	.09	.25	C-2R	1.19	.63	1,500	Auto Signal	39
23	40	Miniature Screw	6.3	.15	.50	C-2R	1.19	.89	3,000	Radio	41
24	47	Miniature Bayonet	6.3	.15	.50	C-2R	1.19	.71	3,000	Radio, Coin	39
25	447	Wedge	6.3	.15	.52	C-2V	1.06	.56	1,500	Indicator, Coin	40
26	755	Miniature Bayonet	6.3	.15	.33	C-2R	1.19	.71	20,000	Indicator	39
27	1847	Miniature Bayonet	6.3	.15	.38	C-2R	1.19	.71	5,000+	Radio	39

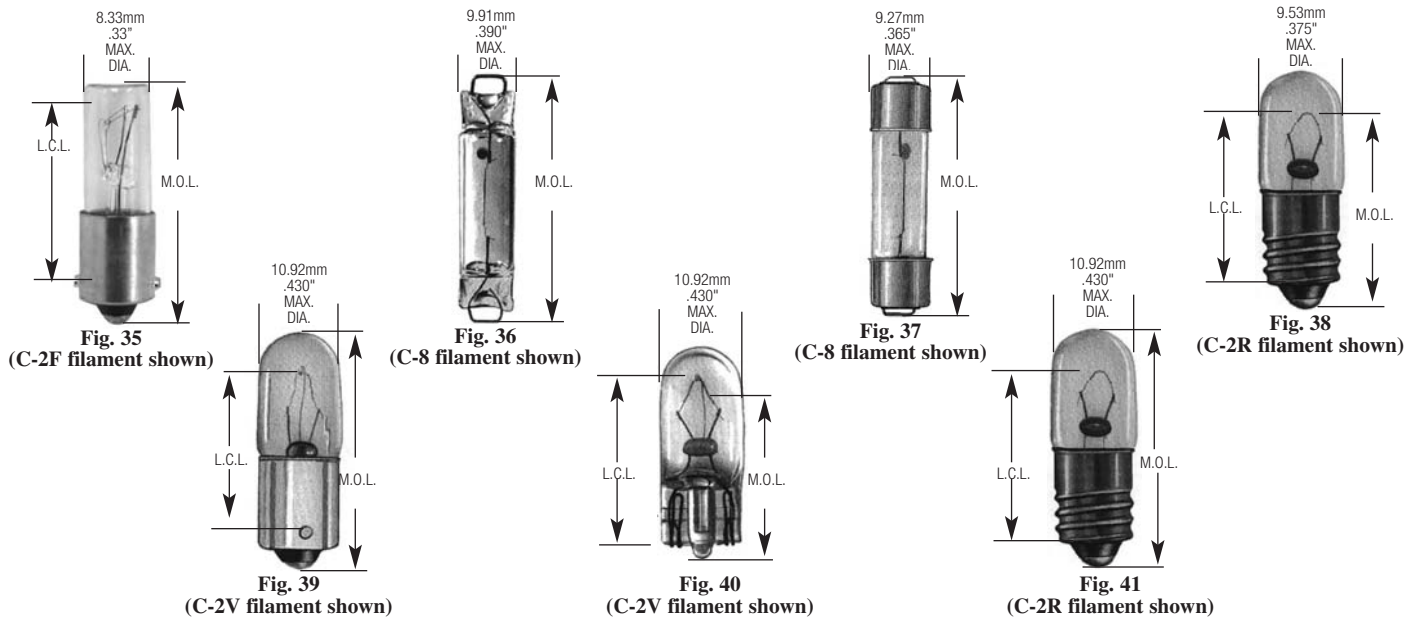

Some lamp pictures are not to scale. Filament and L.C.L. may vary by part number. For filament identification see page 6.

THE PRODUCTS SHOWN REPRESENT ONLY A SMALL PORTION OF OUR STOCK
 PLEASE CALL IF THE PRODUCT YOU NEED IS NOT LISTED
 949/452-0900 • 800/8-LIGHTS • FAX: 800-255-3141

Miniature Lamp Specifications

Line No.	Lamp No.	Base	Des. Volts	Amps or Watts	MSCP	Fil. Type	MOL (inch)	LCL (inch)	Ave Life (Hrs)	Primary Application	Fig. No.
T-3 1/4 Bulb (Continued)											
1	1866	Miniature Bayonet	6.3	.25	.65	C-2R	1.19	.71	5,000	Radio	39
2	44	Miniature Bayonet	6.3	.25	.90	C-2R	1.19	.71	3,000	Indicator, Coin	39
3	46	Miniature Screw	6.3	.25	.90	C-2R	1.19	.90	3,000	Radio	41
4	259	Wedge	6.3	.25	.65	C-2R	1.06	.65	5,000	Radio	40
5	555	Wedge	6.3	.25	.90	C-2R	1.25	.65	3,000	Coin Machine	40
6	1810	Miniature Bayonet	6.3	.40	1.4	C-2R	1.13	.72	3,000	Special Service	39
7	280	Wedge	10.0	.13	.85	C-2V	1.06	.56	250	Indicator	40
8	1408	Miniature Bayonet	10.0	.13	.85	C-2V	1.19	.63	250	Signal	39
9	192	Wedge	13.0	.33	3	C-2V	1.06	.56	1,000	Auto	40
10	1816	Miniature Bayonet	13.0	.33	3	C-2V	1.19	.63	1,000	Aircraft, Auto	39
11	658	Wedge	14.0	.08	.31	C-2F	1.06	.56	15,000	Indicator	40
12	756	Miniature Bayonet	14.0	.08	.31	C-2F	1.13	.63	15,000	Indicator	39
13	161	Wedge	14.0	.19	1	C-2F	1.06	.56	4,000+	Auto Instrument	40
14	1815	Miniature Bayonet	14.0	.20	1.4	C-2V	1.19	.71	3,000	Indicator	39
15	1898	Miniature Bayonet	14.0	.24	2	2C-2R	1.19	.63	7,500	Auto Radio	39
16	158	Wedge	14.0	.24	2	C-2V	1.06	.56	500	Auto Instrument	40
17	1891	Miniature Bayonet	14.0	.24	2	C-2F	1.19	.56	500	Auto	39
18	194	Wedge	14.0	.27	2	C-2F	1.06	.56	2,500	Auto Instrument	40
19	194A	Wedge	14.0	.27	-	C-2F	1.06	-	2,500	Auto Side Marker	40
20	256	Miniature Bayonet	14.0	.27	-	C-2R	1.19	.63	500	Auto Flashing	39
21	1889	Miniature Bayonet	14.0	.27	2	C-2F	1.19	.56	2,000	Auto	39
22	193	Wedge	14.0	.33	2	C-2F	1.06	.56	7,500	Auto Instrument	40
23	1893	Miniature Bayonet	14.0	.33	2	C-2F	1.19	.63	7,500	Auto	39
24	168	Wedge	14.0	.35	3	C-2F	1.06	.56	1,500	Auto Instrument	40
25	3652	Wedge	14.0	.35	5	C-2V	1.06	.50	500	Auto-Krypton	40
26	1813	Miniature Bayonet	14.4	.10	.86	C-2F	1.19	.63	1,000	Radio	39
27	1892	Miniature Bayonet	14.4	.12	.75	C-2F	1.19	.63	1,000	Auto	39
28	1818	Miniature Bayonet	24.0	.17	3.3	C-2F	1.19	.63	250	Aircraft	39
29	1843	Miniature Bayonet	28.0	.022	.20	C-2F	1.19	.63	3,000	Indicator	39

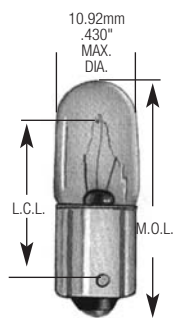


Fig. 39
(C-2V filament shown)

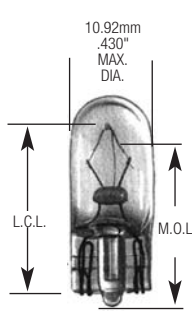


Fig. 40
(C-2V filament shown)

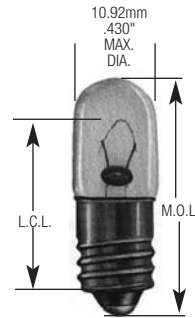



Fig. 41
(C-2R filament shown)

Some lamp pictures are not to scale. Filament and L.C.L. may vary by part number. For filament identification see page 6.

THE PRODUCTS SHOWN REPRESENT ONLY A SMALL PORTION OF OUR STOCK
PLEASE CALL IF THE PRODUCT YOU NEED IS NOT LISTED
949/452-0900 • 800/8-LIGHTS • FAX: 800-255-3141

Miniature Lamp Specifications

Line No.	Lamp No.	Base	Des. Volts	Amps or Watts	MSCP	Fil. Type	MOL (inch)	LCL (inch)	Ave Life (Hrs)	Primary Application	Fig. No.
T-3 1/4 Bulb (Continued)											
1	1819	Miniature Bayonet	28.0	.04	.34	C-2F	1.19	.63	2,500	Indicator	39
2	656	Wedge	28.0	.06	.62	C-2F	1.06	.56	2,500	Indicator	40
3	152	Wedge	28.0	.065	.85	C-2F	1.05	.50	10,000	Indicator	40
4	585	Wedge	28.0	.040	.30	C-2F	1.06	.56	7,000	Indicator	40
5	1829	Miniature Bayonet	28.0	.07	1.0	C-2F	1.19	.63	1,000	Indicator	39
6	657	Wedge	28.0	.08	.62	C-2F	1.06	.56	7,500	Indicator	40
7	757	Miniature Bayonet	28.0	.08	.62	C-2F	1.19	.63	7,500	Indicator	39
8	400	Wedge	28.0	.10	1.6	C-2V	1.06	.56	1,000	Aircraft	40
9	1820	Miniature Bayonet	28.0	.10	1.6	C-2F	1.19	.63	1,000	Indicator	39
10	1821	Miniature Screw	28.0	.17	3.4	C-2F	1.19	.83	500	Indicator	41
11	313	Miniature Bayonet	28.0	.17	3.5	C-2F	1.19	.63	500	Aircraft	39
12	464	Wedge	28.0	.17	3.0	C-2F	1.06	.56	1,500	Aircraft	40
13	1864	Miniature Bayonet	28.0	.17	3.0	C-2F	1.19	.63	1,500	Auto Instrument	39
14	655	Wedge	28.0	.20	3.0	C-2F	1.05	.56	7,000	Indicator	40
15	1873	Miniature Bayonet	28.0	.20	3.0	C-2F	1.19	.63	7,000	Aircraft	39
16	1822	Miniature Bayonet	36.0	.10	2.1	C-2F	1.19	.63	1,000	Indicator	39
17	1828	Miniature Bayonet	37.5	.05	.65	C-2F	1.19	.63	3,000	Indicator	39
18	1823	Miniature Screw	48.0	.10	3.2	C-2F	1.19	.81	1,000	Indicator	41
19	1835	Miniature Bayonet	55.0	.05	1.10	C-2F	1.19	.63	5,000	Indicator	39
T-4 Bulb											
20	1479	Candelabra Screw	14.0	.17	1.7	C-2V	1.38	.94	250	Indicator	41A
21	1480	Candelabra Screw	18.0	.17	1.7	C-2V	1.38	.94	250	Indicator	41A
22	1841	Candelabra Screw	24.0	.17	1.7	C-2F	1.38	.94	250	Indicator	41A
T-4 1/2 Bulb											
23	1414	Miniature Bayonet	14.0	.46	6.0	C-2R	1.38	.63	500	Aircraft	42
24	1495	Miniature Bayonet	28.0	.30	6.0	C-2F	1.38	.63	500	Aircraft	42

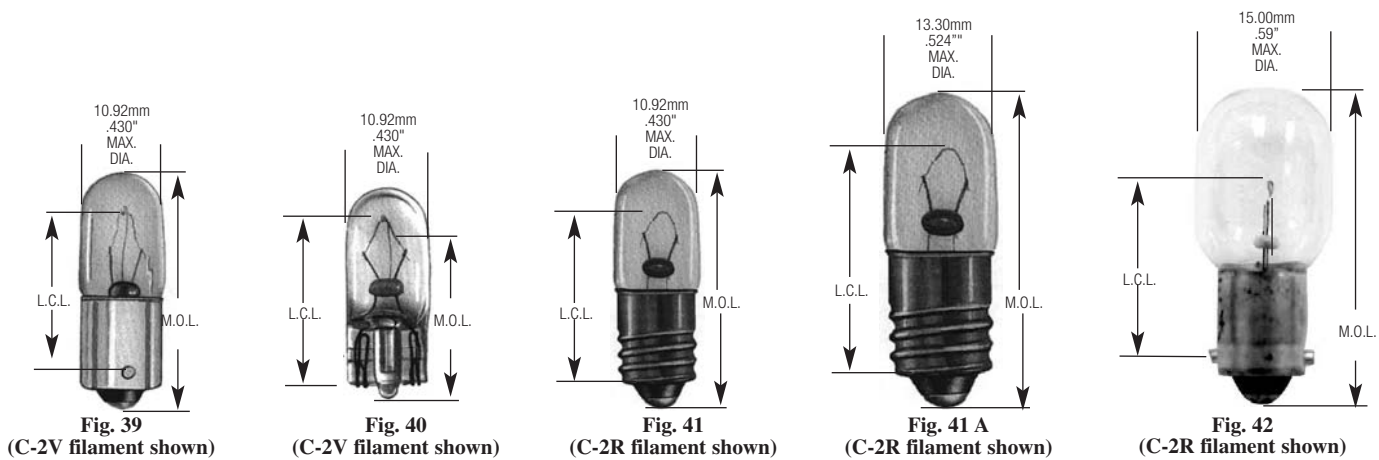

Some lamp pictures are not to scale. Filament and L.C.L. may vary by part number. For filament identification see page 6.

THE PRODUCTS SHOWN REPRESENT ONLY A SMALL PORTION OF OUR STOCK
 PLEASE CALL IF THE PRODUCT YOU NEED IS NOT LISTED
 949/452-0900 • 800/8-LIGHTS • FAX: 800-255-3141

Miniature Lamp Specifications

Line No.	Lamp No.	Base	Des. Volts	Amps or Watts	MSCP	Fil. Type	MOL (inch)	LCL (inch)	Ave Life (Hrs)	Primary Application	Fig. No.
T-4 3/4 Bulb											
1	570	Rigid Loop	12.8	2.10	32	C-8	-	-	600	Auto-Truck	43
2	577	Double End Cap	12.8	2.10	21	C-8	-	-	1,000	Auto	44
T-5 Bulb											
3	1876	S.C. Bayonet	3.5	2.50	6.5	C-6	1.75	1.12	2,000	Special Service	45
4	1874	S.C. Bayonet	3.7	2.75	11.0	C-6	1.75	1.12	100	Instrument	45
5	914	Wedge	4.0	.90	3.5	C-6	1.49	.81	50	Emergency Lighting	46
6	926	Wedge	4.0	1.80	7.5	C-2R	1.49	.81	50	Emergency Lighting	46
7	909	Wedge	6.0	.62	3.0	C-2R	1.49	.81	50	Emergency Lighting	46
8	939	Wedge	6.0	.90	5.4	C-2R	1.49	.81	50	Emergency Lighting	46
9	927	Wedge	6.0	1.20	8.0	C-2R	1.49	.81	50	Emergency	46
10	908	Wedge	6.0	1.50	12.0	C-2R	1.49	.81	50	Emergency	46
11	915	Wedge	12.0	.75	11.0	C-2R	1.49	.81	50	Emergency	46
12	917	Wedge	12.0	1.20	10.0	C-2F	1.49	.81	1,200	Auto	46
13	901	Wedge	12.8	.335	3.7	C-2R	1.49	.81	300	Garden/Security	46
14	918	Wedge	12.8	.56	6.5	C-2R	1.49	.81	500	Garden/Security	46
15	923	Wedge	12.8	.91	12.5	C-2R	1.49	.81	500	Garden/Security	46
16	922	Wedge	12.8	.98	15.0	C-2R	1.49	.81	200	Auto	46
17	912	Wedge	12.8	1.00	12.0	C-2R	1.49	.81	1,000	Auto	46
18	912F	Wedge	12.8	1.00	-	C-2R	1.49	.81	1,000	Auto	46
19	921	Wedge	12.8	1.40	21.0	C-2R	1.49	.81	1,000	Auto	46
20	921F	Wedge	12.8	1.40	-	C-2R	1.49	.81	1,000	Auto	46
21	916	Wedge	13.0	.54	2.0	C-2F	1.49	.81	10,000	Auto	46
22	916NA	Wedge	13.0	.54	-	C-2F	1.49	.81	10,000	Auto	46
23	906	Wedge	13.0	.69	6.0	C-2F	1.49	.81	1,000	Auto	46
24	906F	Wedge	13.0	.69	-	C-2F	1.49	.81	1,000	Auto	46
25	904	Wedge	13.5	.69	4.0	C-2F	1.49	.81	5,000	Auto	46
26	928	Wedge	28.0	.30	6.0	C-2F	1.49	.81	500	Indicator	46

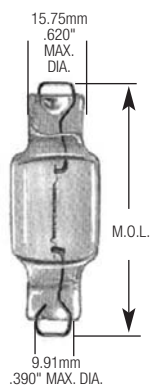


Fig. 43
(C-8 filament shown)



Fig. 44
(C-8 filament shown)

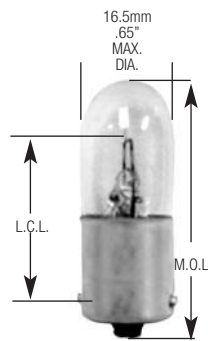


Fig. 45
(C-6 filament shown)

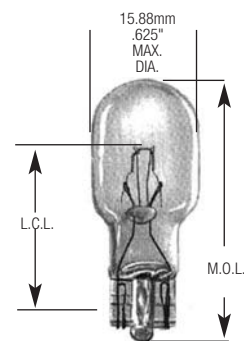


Fig. 46
(C-2F filament shown)

Some lamp pictures are not to scale. Filament and L.C.L. may vary by part number. For filament identification see page 6.

THE PRODUCTS SHOWN REPRESENT ONLY A SMALL PORTION OF OUR STOCK
PLEASE CALL IF THE PRODUCT YOU NEED IS NOT LISTED
949/452-0900 • 800/8-LIGHTS • FAX: 800-255-3141

Miniature Lamp Specifications

Line No.	Lamp No.	Base	Des. Volts	Amps or Watts	MSCP	Fil. Type	MOL (inch)	LCL (inch)	Ave Life (Hrs)	Primary Application	Fig. No.
T-6 Bulb											
1	3496	D.C. Index	12.8	2.10	43	C-6	2.00	1.25	-	Krypton Auto Stop Signal Park	47
2	3497	S.C. Bayonet	12.8	2.2	45	C-6	2.00	1.25	-	Krypton Auto Stop Signal High Mount	48
T-6 1/2 Bulb											
3	7440	Wedge	13.5	25W	36	C-6	1.75	1.14	300	Auto 12V, 21W	49
4	7443	Wedge	13.5	25/6W	35/2.8	C-6/6.6	1.75	.98	300/1000	Auto 12V, 21W/5W	49
TL-3Bulb											
5	112	Miniature Screw	1.2	.22	-	S-2	-	-	5	Flashlight - 1AA	50
6	222	Miniature Screw	2.25	.25	-	C-6	-	-	5	Flashlight - 2AA	50
7	243	Miniature Screw	2.33	.27	-	C-2R	-	-	10	Flashlight 2 C-Cells	50

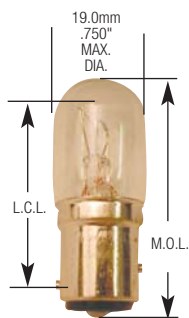


Fig. 47
(C-6/C-6 filament shown)

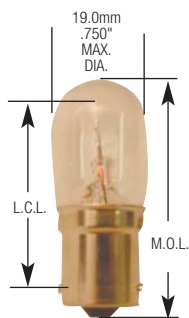


Fig. 48
(C-6 filament shown)

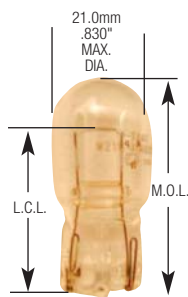


Fig. 49
(C-6 filament shown)

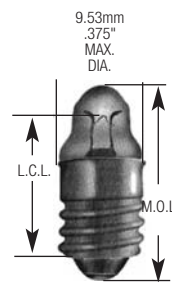


Fig. 50
(C-2R filament shown)

Some lamp pictures are not to scale. Filament and L.C.L. may vary by part number. For filament identification see page 6.

THE PRODUCTS SHOWN REPRESENT ONLY A SMALL PORTION OF OUR STOCK
PLEASE CALL IF THE PRODUCT YOU NEED IS NOT LISTED
949/452-0900 • 800/8-LIGHTS • FAX: 800-255-3141