



WORLDWIDE PARTNER

Commercial Products & Solutions

[site search](#)
[home](#)
[products](#)
[education / resources](#)
[lighting applications](#)
[Where to Buy](#) | [FAQs](#) | [Contact Us](#) | [EliteNet](#)
[Products](#) > 43574

43574 – H7554 BULK

GE PAR36 - Emergency Building Light; Emergency Building

GENERAL CHARACTERISTICS

Lamp type	Sealed Beam - PAR
Bulb	PAR36
Base	Screw Terminals
Filament	C-6
Product Technology	Incandescent
Wattage	20
Voltage	6
Rated Life	50 hrs
Primary Application	Emergency Building Light; Emergency Building

PHOTOMETRIC CHARACTERISTICS


Beam Spread - Horizontal	30° - 10 %
Beam Spread - Vertical	20° - 10 %
Max. Beam Candlepower (MBCP) (MAX)	1400

DIMENSIONS

Maximum Overall Length (MOL)	2.7500 in (69.8 mm)
Bulb Diameter (DIA)	4.500 in (114.3 mm)

PRODUCT INFORMATION

Product Code	43574
Description	H7554 BULK
ANSI Code	H7554
Standard Package Case	
Standard Package GTIN	10043168435748
Standard Package Quantity	60
Sales Unit	Bulk
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	60
UPC	043168435741

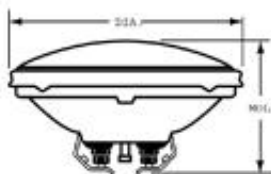

Bulb



Base



Filament


[View Larger](#)

ADDITIONAL RESOURCES

[Catalogs](#)
[Disposal Policies & Recycling Information](#)

CAUTIONS & WARNINGS

[See list of cautions & warnings.](#)

[Return To Top](#)

[Home](#) | [Products](#) | [EliteNet](#) | [Education/Resources](#) | [Lighting Applications](#) | [Where to Buy](#) | [FAQs](#) | [Contact Us](#) | [Site Map](#)
[Products for Your Home](#) | [Press Room](#) | [Corporate](#) | [Investor Information](#) | [Privacy Policy](#) | [Accessibility Statement](#) | [Terms of Use](#)

Copyright General Electric Company 1997-2009