


Presented By: Candela Corporation
Contact Phone: (800) 922-9226
Contact E-mail: sales@candelacor.com

Customer Name:
Project Name:
Fixture Type:



GE
Lighting

43712 - Q1000T3/CL-6PK
GE T3

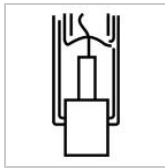

GENERAL CHARACTERISTICS

Lamp Type	Halogen - Single-Ended
Bulb	T3
Base	Recessed Single Contact (R7s)
Filament	C-8
Wattage	1000
Voltage	240
Rated Life	2000 hrs

PHOTOMETRIC CHARACTERISTICS

Initial Lumens	21500
Color Temperature	3050 K
Nominal Initial Lumens per Watt	21

ELECTRICAL CHARACTERISTICS

Burn Position	Horizontal
---------------	------------

DIMENSIONS

Maximum Overall Length (MOL)	10.0630 in(255.6 mm)
Bulb Diameter (DIA)	0.375 in(9.5 mm)
Bulb Diameter (DIA) (MAX)	0.375 in(9.5 mm)
Light Center Length (LCL)	6.438 in(163.5 mm)

PRODUCT INFORMATION

Product Code	43712
Description	Q1000T3/CL-6PK
Standard Package	Master
Standard Package GTIN	10043168437124
Standard Package Quantity	144
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	144
UPC	043168437127

CAUTIONS & WARNINGS

Caution

- Lamp may shatter and cause injury if broken
 - Dispose of lamp in a closed container.
 - Do not use lamp if outer glass is scratched or broken.

Warning

- Lamp emits UV radiation which may cause eye/skin injury. RG-3
 - Avoid exposure of eyes and skin to unshielded lamp.
- Risk of Electric Shock
 - Turn power off before inspection, installation or removal.
- Risk of Burn
 - Allow lamp to cool before handling.
 - Turn power off before installing lamp.
- Risk of Fire
 - Fire Hazard! Do not use in Torchieres or other indoor residential fixtures.
 - Keep combustible materials away from lamp.
 - Use in enclosed fixture rated for this product.
- Pressurized lamp--unexpected rupture may cause injury, fire, or property damage
 - Do not exceed 110% of rated voltage.
 - Do not touch glass with bare hands.
 - Do not use lamp if outer glass is scratched or broken.
 - Operate lamp only in specified position -- see instructions.
 - Use eye protection when handling lamp.
 - Use in enclosed fixture rated for this product.