

**Presented By:** Candela Corporation  
Contact Phone: (800) 922-9226  
Contact E-mail: sales@candelacor.com

Customer Name:  
Project Name:  
Fixture Type:



GE  
Lighting

**23832 - Q1500T3/CL**  
GE T3



### GENERAL CHARACTERISTICS

Lamp Type	Halogen - Single-Ended
Bulb	T3
Base	Recessed Single Contact (R7s)
Filament	C-8
Wattage	1500
Voltage	277
Rated Life	2000 hrs

### PHOTOMETRIC CHARACTERISTICS

Initial Lumens	34400
Color Temperature	3050 K
Nominal Initial Lumens per Watt	22

### ELECTRICAL CHARACTERISTICS


Burn Position	Horizontal
---------------	------------

### DIMENSIONS

Maximum Overall Length (MOL)	10.0630 in(255.6 mm)
Bulb Diameter (DIA)	0.375 in(9.5 mm)
Bulb Diameter (DIA) (MAX)	0.375 in(9.5 mm)
Light Center Length (LCL)	6.250 in(158.8 mm)

### PRODUCT INFORMATION

Product Code	23832
Description	Q1500T3/CL
Standard Package	Case
Standard Package GTIN	10043168238325
Standard Package Quantity	12
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	12
UPC	043168238328

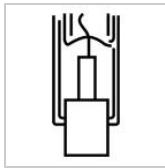

### CAUTIONS & WARNINGS

#### Caution

- Lamp may shatter and cause injury if broken
  - Dispose of lamp in a closed container.
  - Do not use lamp if outer glass is scratched or broken.

#### Warning

- Risk of Electric Shock
  - Turn power off before inspection, installation or removal.
- Risk of Burn
  - Allow lamp to cool before handling.
  - Turn power off before installing lamp.
- Lamp emits UV radiation which may cause eye/skin injury. RG-3
  - Avoid exposure of eyes and skin to unshielded lamp.
- Risk of Fire
  - Fire Hazard! Do not use in Torchieres or other indoor residential fixtures.
  - Keep combustible materials away from lamp.
  - Use in enclosed fixture rated for this product.
- Pressurized lamp--unexpected rupture may cause injury, fire, or property damage
  - Do not exceed 110% of rated voltage.
  - Do not touch glass with bare hands.
  - Do not use lamp if outer glass is scratched or broken.
  - Operate lamp only in specified position -- see instructions.
  - Use eye protection when handling lamp.
  - Use in enclosed fixture rated for this product.