

Presented By: Candela Corporation
Contact Phone: (800) 922-9226
Contact E-mail: sales@candelacorp.com

Customer Name:
Project Name:
Fixture Type:



GE
Lighting

20815 - Q20MR16/C/NSP15
GE ConstantColor® Precise™ MR16



GENERAL CHARACTERISTICS

Lamp Type	Halogen - MR
Bulb	MR16
Base	2-Pin (GX5.3)
Filament	C-6
Wattage	20
Voltage	12
Rated Life	5000 hrs
Lamp Enclosure Type (LET)	Open or enclosed fixtures

PHOTOMETRIC CHARACTERISTICS


Center Beam Candlepower (CBCP)	3750
Color Temperature	2900 K

DIMENSIONS

Maximum Overall Length (MOL)	1.875 cm
Bulb Diameter (DIA)	2 cm
Bulb Diameter (DIA) (MAX)	2 cm

PRODUCT INFORMATION

Product Code	20815
Description	Q20MR16/C/NSP15
ANSI Code	ESX
Standard Package	BUNDLE
Standard Package GTIN	00043168208154
Standard Package Quantity	20
Sales Unit	Unit
No Of Items Per Sales Unit	1
No Of Items Per Standard Package	20
UPC	043168990097

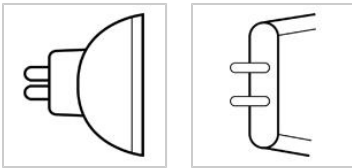

CAUTIONS & WARNINGS

Caution

- Lamp may shatter and cause injury if broken
 - Dispose of lamp in a closed container.
 - Do not use lamp if outer glass is scratched or broken.

Warning

- Pressurized lamp--unexpected rupture may cause injury, fire, or property damage
 - Do not touch glass with bare hands.
 - Do not use lamp if outer glass is scratched or broken.
 - Use eye protection when handling lamp.
 - Use in enclosed fixture rated for this product.
- Risk of Burn
 - Allow lamp/fixture to cool before handling.
 - Turn power off before installing lamp.
- Risk of Fire
 - Keep combustible materials away from lamp.
 - Use in enclosed fixture rated for this product-- see instructions.