




PRODUCT SPECIFICATION

CATALOG NUMBER: 03482
DESCRIPTION: POLAR/SOLAR Plus™ SEOW adapter cord with Tri-Source® three outlet cord connector with power indicator light
APPROVALS: UL Listed Adapter Cord Set; CUL Listed or CSA Certified

CONSTRUCTION PARAMETERS:

Gauge: 12/3
Conductor: 65/30 BC
Cable jacket material: TPE, yellow
Overall cable O.D. (nom): 0.585 in
Cord rating: Extra Hard Usage per the National Electrical Code
Cable legend type: Indent print

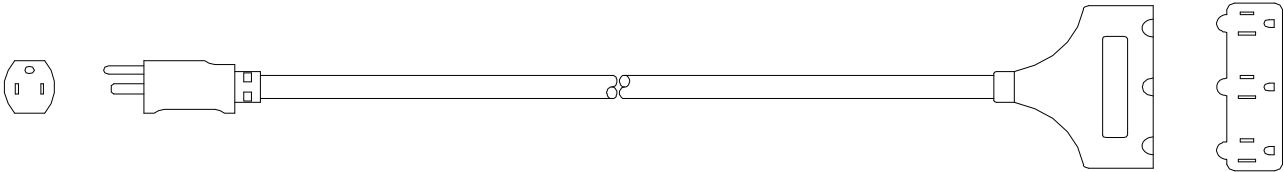

Note: Plug and connector style may vary

Cord set length: 2 ft
Attachment plug configuration: NEMA 5-15P
Cord connector configuration: NEMA 5-15R x 3
Plug and connector material: Clear PVC, with neon power indicator lamp in the cord connector

ELECTRICAL AND ENVIRONMENTAL PROPERTIES:

Cable temperature rating: -50 to +90 °C
Nominal operating voltage: 125 VAC
Maximum operating current: 15A

The information presented here is, to the best of our knowledge, true and accurate. However, since conditions of use are beyond our control, all recommendations or suggestions are presented without guarantee or responsibility on our part. We disclaim all liability in connection with the use of information contained herein or otherwise.

This specification is proprietary intellectual property of Coleman Cable Inc. Any information contained herein shall not be disclosed to any party without written consent of Coleman Cable Inc.