




PRODUCT SPECIFICATION

CATALOG NUMBER: See table below
DESCRIPTION: SJTW cord set with Power Block connector
APPROVALS: UL Listed Outdoor Use Cord Set

CONSTRUCTION PARAMETERS:

Conductor: See table below
Cable jacket material: PVC
Overall cable O.D. (nom): See table below
Cord rating: Hard Usage per the National Electrical Code
Cable legend: Indent print
Cable color: See table below

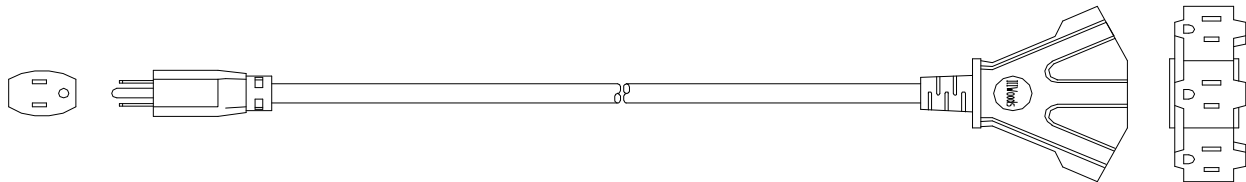

Note: Plug and connector style may vary

Attachment plug configuration: NEMA 5-15P
Cord connector configuration: NEMA 5-15R x 3
Plug and connector material: PVC
Plug and connector color: Same as cable color

ELECTRICAL PROPERTIES:

Cable temperature rating: -40 to +60 °C
Nominal operating voltage: 125 VAC
Maximum operating current: See table below

Catalog no.	Length	Color	Conductor	Cable O.D. (nom)	Current rating
0825	25 ft	Orange	14/3 41/30 BC	0.352 in	15A
0826	50 ft	Orange			
0827	100 ft	Orange			13A
0819	50 ft	Orange	12/3 65/30 BC	0.420 in	15A
0820	100 ft	Orange			
4027	25 ft	Yellow	10/3 104/30 BC	0.567 in	15A
4028	50 ft	Yellow			
4029	100 ft	Yellow			

The information presented here is, to the best of our knowledge, true and accurate. However, since conditions of use are beyond our control, all recommendations or suggestions are presented without guarantee or responsibility on our part. We disclaim all liability in connection with the use of information contained herein or otherwise.

This specification is proprietary intellectual property of Coleman Cable Systems. Any information contained herein shall not be disclosed to any party without written consent of Coleman Cable Systems.