




PRODUCT SPECIFICATION

CATALOG NUMBER: See table below
DESCRIPTION: Tri-Source® three receptacle extension cord, with a power indicator lamp in the cord connector
APPROVALS: UL/CSA or UL/CUL outdoor use cord set

CONSTRUCTION PARAMETERS:

Conductor: See table below
 Jacket material: PVC
 Jacket color: See table below
 Overall cable O.D. (nom): See table below
 Cord rating: Hard Usage per the National Electrical Code
 Attachment plug configuration: NEMA 5-15P
 Cord connector configuration: NEMA 5-15R x 3
 Plug and connector material: Clear PVC, with a neon power indicator lamp in the cord connector block

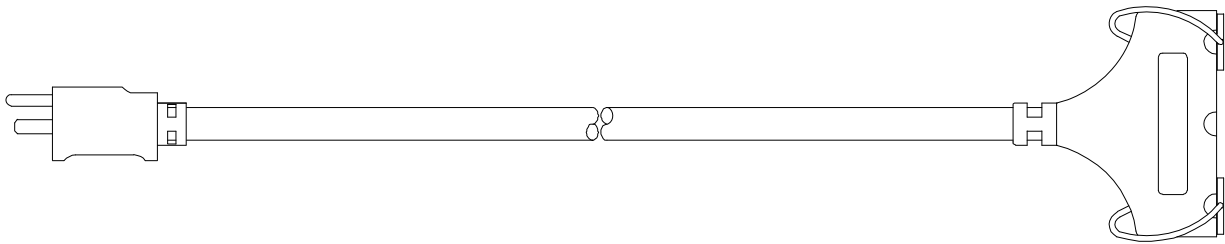

ELECTRICAL PROPERTIES:

Cable temperature rating: -20 to +60 °C
 Nominal operating voltage: 125 VAC
 Maximum operating current: 15A

Catalog number	Length	Cable type	Color	Conductor	Cable O.D. (nom)
04287	25 ft	SJTOW	Black	14 AWG, 41/30 BC	0.352 in
04187	25 ft	SJTW	Yellow	12 AWG, 65/30 BC	0.420 in
04188	50 ft				
04189	100 ft				
04388	50 ft			10 AWG, 104/30 BC	
04389	100 ft				

The information presented here is, to the best of our knowledge, true and accurate. However, since conditions of use are beyond our control, all recommendations or suggestions are presented without guarantee or responsibility on our part. We disclaim all liability in connection with the use of information contained herein or otherwise.

This specification is proprietary intellectual property of Coleman Cable Inc. Any information contained herein shall not be disclosed to any party without written consent of Coleman Cable Inc.

CUSTOMER APPROVAL: Approved by: _____ Date: _____
 Title: _____