


- Attaches conduit, flexible conduit or cables to standard strut channels.
- B1506S designed to secure and support MC/AC cables.
- Unique one-piece design eliminates handling of hardware and allows easy installation and removal in side-by-side conduit runs.
- Anti-rock feature prevents clamp from disengaging during installation.
- Finish: Zinc-Plated

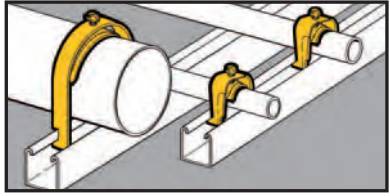

## Conduit Strut Clamps



B1508  
thru  
B1520



B1506S  
thru  
B1524S



B1532S  
thru  
B1564S



UPC/Part Number	Catalog Number	Conduit Size EMT Rigid		OD Range Min Max		Static Load Cap.	Box Qty.
781011 63150	<b>B1508</b>	1/2"	--	--	--	200 Lbs.	100
781011 63154	<b>B1512</b>	3/4"	1/2"	--	--	200 Lbs.	100
781011 63157	<b>B1516</b>	1"	3/4"	--	--	300 Lbs.	100
781011 63160	<b>B1520</b>	1 1/4"	1"	--	--	300 Lbs.	100
782051 44495	<b>B1506S*</b>	3/8"*	--	.400	.630	200 Lbs.	100
781011 63164	<b>B1508S</b>	1/2"	--	.250	.680	200 Lbs.	100
781011 63168	<b>B1512S</b>	3/4"	1/2"	.500	.840	200 Lbs.	100
781011 63171	<b>B1516S</b>	1"	3/4"	.750	1.050	300 Lbs.	100
781011 63177	<b>B1520S</b>	1 1/4"	1"	1.125	1.315	300 Lbs.	100
781011 63182	<b>B1524S</b>	1 1/2"	1 1/4"	1.375	1.660	400 Lbs.	50
781011 63188	<b>B1532S</b>	2"	1 1/2"	1.875	2.200	400 Lbs.	50
781011 63193	<b>B1534S</b>	--	2"	2.125	2.375	400 Lbs.	25
781011 63199	<b>B1540S</b>	2 1/2"	2 1/2"	2.625	2.875	400 Lbs.	25
781011 63205	<b>B1548S</b>	3"	3"	3.250	3.500	400 Lbs.	25
781011 63211	<b>B1556S</b>	3 1/2"	3 1/2"	3.750	4.000	400 Lbs.	10
781011 63215	<b>B1564S</b>	4"	4"	4.250	4.500	400 Lbs.	10

Patent #5022614

- \* B1506S will accept the following  
 AC Cable 14/2, 14/3, 14/4, 12/2, 12/3, 12/4, 10/2, 10/3, 10/4  
 MC Cable 14/2, 14/3, 14/4, 12/2, 12/3, 12/4, 10/2, 10/3, 10/4

Read safety/installation instruction sheets in packages before use.