


- Attaches conduit, flexible conduit or cables to standard strut channels.
- B1506S designed to secure and support MC/AC cables.
- Unique one-piece design eliminates handling of hardware and allows easy installation and removal in side-by-side conduit runs.
- Anti-rock feature prevents clamp from disengaging during installation.
- Finish: Zinc-Plated

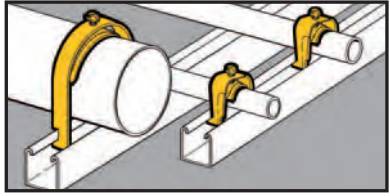

Conduit Strut Clamps



B1508
thru
B1520



B1506S
thru
B1524S



B1532S
thru
B1564S



UPC/Part Number	Catalog Number	Conduit Size		OD Range		Static Load Cap.	Box Qty.
		EMT	Rigid	Min	Max		
781011 63150	B1508	1/2"	--	--	--	200 Lbs.	100
781011 63154	B1512	3/4"	1/2"	--	--	200 Lbs.	100
781011 63157	B1516	1"	3/4"	--	--	300 Lbs.	100
781011 63160	B1520	1 1/4"	1"	--	--	300 Lbs.	100
Note: Clamps without saddle are not recommended for flexible conduit or cable.							
782051 44495	B1506S*	3/8"*	--	.400	.630	200 Lbs.	100
781011 63164	B1508S	1/2"	--	.250	.680	200 Lbs.	100
781011 63168	B1512S	3/4"	1/2"	.500	.840	200 Lbs.	100
781011 63171	B1516S	1"	3/4"	.750	1.050	300 Lbs.	100
781011 63177	B1520S	1 1/4"	1"	1.125	1.315	300 Lbs.	100
781011 63182	B1524S	1 1/2"	1 1/4"	1.375	1.660	400 Lbs.	50
781011 63188	B1532S	2"	1 1/2"	1.875	2.200	400 Lbs.	50
781011 63193	B1534S	--	2"	2.125	2.375	400 Lbs.	25
781011 63199	B1540S	2 1/2"	2 1/2"	2.625	2.875	400 Lbs.	25
781011 63205	B1548S	3"	3"	3.250	3.500	400 Lbs.	25
781011 63211	B1556S	3 1/2"	3 1/2"	3.750	4.000	400 Lbs.	10
781011 63215	B1564S	4"	4"	4.250	4.500	400 Lbs.	10

Patent #5022614

- * B1506S will accept the following
 AC Cable 14/2, 14/3, 14/4, 12/2, 12/3, 12/4, 10/2, 10/3, 10/4
 MC Cable 14/2, 14/3, 14/4, 12/2, 12/3, 12/4, 10/2, 10/3, 10/4

Read safety/installation instruction sheets in packages before use.