



Conduit & Cable



Break-Apart Conduit Clamps

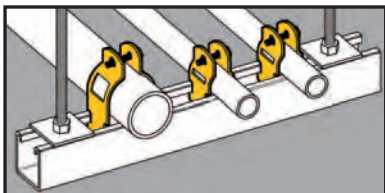

BPC-8 thru BPC-32

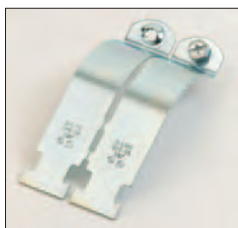


BPC-40 thru BPC-64



- Patented Multi-Grip design fits Rigid, IMC or EMT conduit.
- Convenient break-apart clamp features retained bolt and 5/16" thread impression to eliminate handling of nuts and bolts.
- Finish: Zinc-Plated.
- Static Load Capacity: 200 lbs.

Static Load Capacity

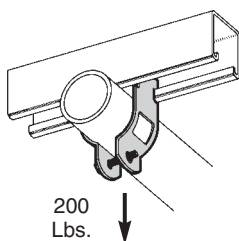

UPC/Part Number	Catalog Number	Rigid or EMT Conduit Size	Box Qty.
781011 01676	BPC-8	1/2"	100
781011 01677	BPC-12	3/4"	100
781011 01680	BPC-16	1"	100
781011 01679	BPC-20	1 1/4"	50
781011 01678	BPC-24	1 1/2"	50
781011 01681	BPC-32	2"	50
781011 03977	BPC-40	2 1/2"	50
781011 03978	BPC-48	3"	50
781011 03979	BPC-56	3 1/2"	25
781011 03981	BPC-64	4"	25

Patent #4044428

Read safety/installation instruction sheets in packages before use.