


- New BMC3 plate is available to support multiple conduit runs.
- Riveted assembly secures electrical boxes and conduit runs to beam flanges 1/8" to 1/2" thick.
- Provides support for conduit on either side of electrical box.
- Assemblies using BMC3 plate include center conduit clamp. Additional conduit clamps may be purchased separately.



Guide-Rite™ Conduit & Box Support Fasteners

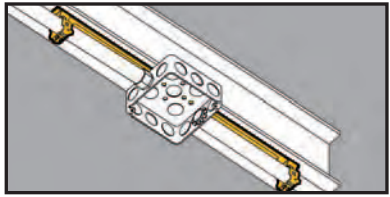

- See Ruff-IN™ brochure for pre-fab box assemblies.



UPC/Part Number	Catalog Number	Conduit Size	Flange Thickness	Box Qty.
781011 03583	BG6-S18-U24 *	3/8"	1/8" to 1/4"	25
781011 03584	BG6-S18-U58 *	3/8"	5/16" to 1/2"	25
781011 03579	BG812-S18-U24	1/2", 3/4"	1/8" to 1/4"	25
781011 03580	BG812-S18-U58	1/2", 3/4"	5/16" to 1/2"	25
781011 03581	BG16-S18-U24	1"	1/8" to 1/4"	25
781011 03582	BG16-S18-U58	1"	5/16" to 1/2"	25

Patent #4958792

With Multiple Conduit Plate

782051 52813	BG6-S18-U24-MC3 *	3/8"	1/8" to 1/4"	25
782051 52814	BG6-S18-U58-MC3 *	3/8"	5/16" to 1/2"	25
782051 52815	BG812-S18-U24-MC3	1/2", 3/4"	1/8" to 1/4"	25
782051 52816	BG812-S18-U58-MC3	1/2", 3/4"	5/16" to 1/2"	25
782051 52817	BG16-S18-U24-MC3	1"	1/8" to 1/4"	25
782051 52823	BG16-S18-U58-MC3	1"	5/16" to 1/2"	25

- * BG-6 will accept the following range $\varnothing.420 - \varnothing.675$:
14/2 thru 10/4 MC/AC cable and 5/16 or 3/8 flexible conduit

Read safety/installation instruction sheets in packages before use.