



Features: The NNP pad is made of oil-resistant neoprene. The pad has an alternate height rib pattern to minimize slip. Recommended load is 50 Lbs. per inch² with a range of 25-70 Lbs. per inch². The NNP type has a deflection of 1/8" (3.1mm). For greater deflection, use multiple pads in layers.

Typical Applications: Air conditioners, cooling towers, compressors, fans, generators, pumps, piping, process equipment, transformers, etc.

NNP Type - Ribbed Neoprene Vibration Pad

Use: Dampen noise and vibration in floor caused by medium and high speed equipment.

Part No.	Rated Load		Dimensions				Std. Pkg.	Wt. Each	
	Lbs.	(kN)	L in.	(mm)	W in.	(mm)		Lbs.	(kg)
NNP-4	200	(.89)	2"	(50.8)	2"	(50.8)	48	.04	(.02)
NNP-9	450	(2.00)	3"	(76.2)	3"	(76.2)	36	.10	(.05)
NNP-16	800	(3.56)	4"	(101.6)	4"	(101.6)	24	.17	(.08)
NNP-36	1800	(8.00)	6"	(152.4)	6"	(152.4)	24	.39	(.18)
NNP-81	4050	(18.01)	9"	(228.6)	9"	(228.6)	Bulk	.87	(.39)
NNP-324	16200	(72.06)	18"	(457.2)	18"	(457.2)	6	3.50	(1.59)

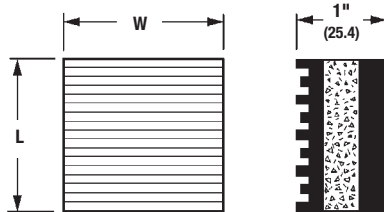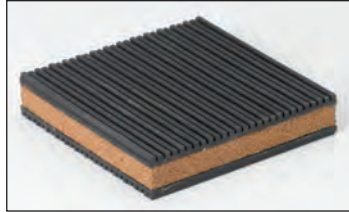

Features: The CNP pad is made of oil-resistant neoprene. The pad has an alternate height rib pattern to minimize slip. Recommended load is 50 Lbs. per inch² with a range of 25-70 Lbs. per inch². The CNP type is rated at 3/16" (4.7mm) deflection. For greater deflection, use multiple pads in layers.

Typical Applications: Air conditioners, cooling towers, compressors, fans, generators, pumps, piping, process equipment, transformers, etc.

CNP Type - Cork and Ribbed Neoprene Vibration Pad

Use: Dampen noise and vibration in floor caused by medium and high speed equipment.

Part No.	Rated Load		Dimensions				Std. Pkg.	Wt. Each	
	Lbs.	(kN)	L in.	(mm)	W in.	(mm)		Lbs.	(kg)
CNP-4	200	(.89)	2"	(50.8)	2"	(50.8)	48	.07	(.03)
CNP-9	450	(2.00)	3"	(76.2)	3"	(76.2)	36	.16	(.07)
CNP-16	800	(3.56)	4"	(101.6)	4"	(101.6)	24	.28	(.13)
CNP-25	1250	(5.56)	5"	(127.0)	5"	(127.0)	24	.44	(.20)
CNP-36	1800	(8.00)	6"	(152.4)	6"	(152.4)	24	.63	(.29)
CNP-81	4050	(18.01)	9"	(228.6)	9"	(228.6)	Bulk	1.40	(.64)
CNP-324	16200	(72.06)	18"	(457.2)	18"	(457.2)	6	5.60	(2.54)
CNP-3x36	5400	(24.02)	3"	(76.2)	36"	(914.4)	6	1.89	(.86)
CNP-4x36	7200	(32.02)	4"	(101.6)	36"	(914.4)	6	2.52	(1.14)